

## Technical data sheet

### Adapter cable

Part no.: 50134949

KDS ET-RJ45-A-USB3-A-P4-000

#### Contents

- Technical data
- Electrical connection

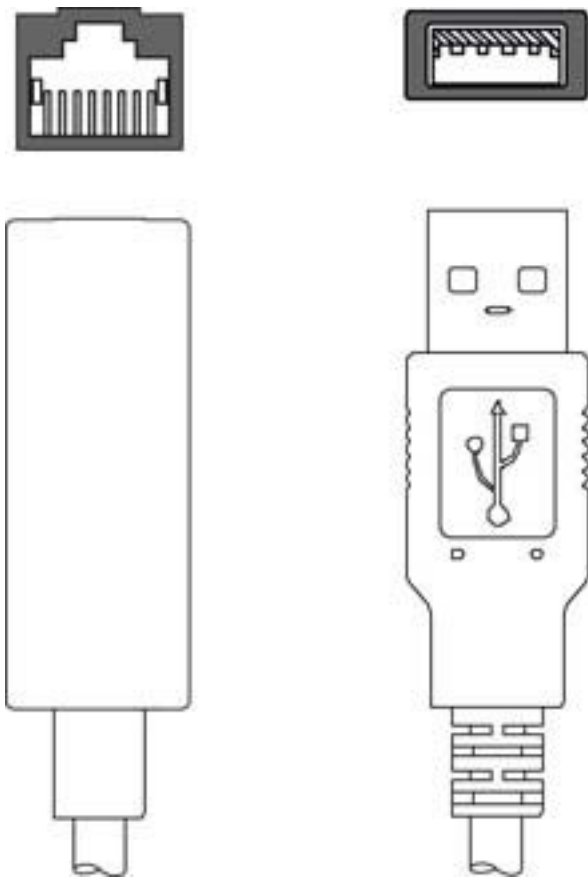


Figure can vary

## Technical data

### Basic data

Suitable for interface	Ethernet
------------------------	----------

### Interface

#### Ethernet

Transmission speed	10/100/1000Mbps RJ45 Ethernet port
--------------------	------------------------------------

### Connection

Number of connections	2 Piece(s)
-----------------------	------------

#### Connection 1

Type of connection	RJ45
Version	Axial

#### Connection 2

Type of connection	USB
Connector type	USB 3.0 Standard-A

### Mechanical data

Design	Cubic
Dimension (W x H x L)	71 mm x 26 mm x 16.2 mm
Housing color	White

### Environmental data

Ambient temperature, operation	0 ... 40 °C
Ambient temperature, storage	-40 ... 70 °C

### Certifications

Degree of protection	IP 20
Certifications	FCC
	RoHS

### Software

System requirements	Windows XP/Vista/7/8/8.1, Mac OS X 10.5/10.6/10.7/10.8/10.9/10.10/, Linux-based system
---------------------	--

### Classification

Customs tariff number	85176200
eCl@ss 5.1.4	27069190
eCl@ss 8.0	27069190
eCl@ss 9.0	27069190
eCl@ss 10.0	27060313
eCl@ss 11.0	27060313
ETIM 5.0	EC001855
ETIM 6.0	EC001855
ETIM 7.0	EC001855

## Electrical connection

### Connection 1

Type of connection	RJ45
--------------------	------

### Connection 2

Type of connection	USB
Connector type	USB 3.0 Standard-A