


Technical data sheet Interconnection cable

Part no.: 50103413

KB RS232/ext IT4xxx

Contents

- Technical data
- Electrical connection

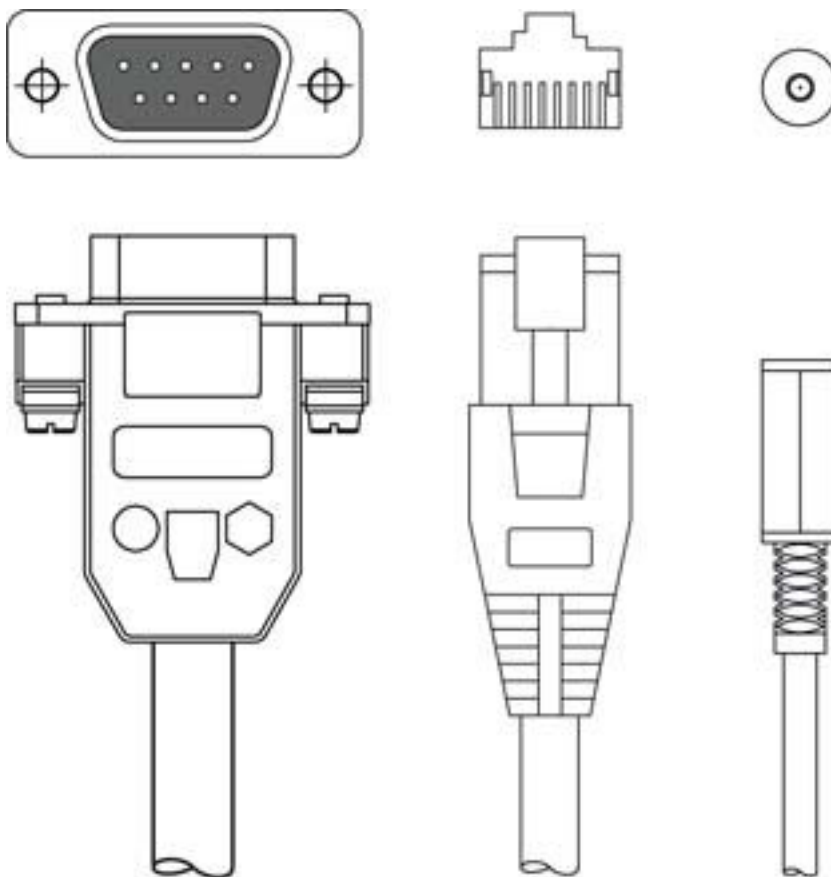

For illustration purposes only

Technical data

Basic data

Suitable for	IT 38xx series mobile bar code readers
Suitable for interface	RS 232

Connection

Connection 1

Type of connection	Sub-D
Type	Female
No. of pins	9 -pin
Version	Axial

Connection 2

Type of connection	RJ41
--------------------	------

Connection 3

Type of connection	Connector
Thread size	Pluggable
Type	Female
No. of pins	4 -pin
Version	Axial

Cable properties

Number of conductors	10 Piece(s)
Sheathing color	Black
Shielded	Yes
Cable design	Helix cable
Cable diameter (external)	5 mm
Cable length	2,600 mm
Sheathing material	PVC
Suitability for drag chains	No

Classification

Customs tariff number	85444290
ECLASS 5.1.4	27279201
ECLASS 8.0	27279218
ECLASS 9.0	27060311
ECLASS 10.0	27060311
ECLASS 11.0	27060311
ECLASS 12.0	27060311
ECLASS 13.0	27060311
ECLASS 14.0	27060311
ECLASS 15.0	27060311
ETIM 5.0	EC001855
ETIM 6.0	EC001855
ETIM 7.0	EC001855
ETIM 8.0	EC001855
ETIM 9.0	EC001855
ETIM 10.0	EC001855

Electrical connection

Connection 1

Type of connection	Sub-D
Type	Female
No. of pins	9 -pin
Version	Axial

Connection 2

Type of connection	RJ41
--------------------	------

Connection 3

Type of connection	Connector
Thread size	Pluggable
Type	Female
No. of pins	4 -pin
Version	Axial