



Part no.: 150756
CB-M12-CC12
Interconnection cable

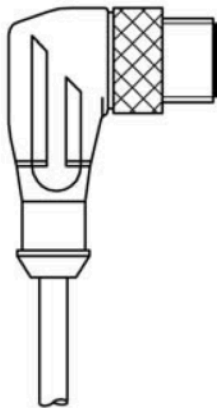


Figure can vary

Contents

- Technical data
- Electrical connection

Part no.: 150756 – CB-M12-CC12 – Interconnection cable

Technical data

Electrical data

Connection

Connection 1

Type of connection	Connector
Thread size	M12
Type	Female
No. of pins	4 -pin
Encoding	A-coded
Design	Axial

Connection 2

Type of connection	Connector
Thread size	M12
Type	Male
No. of pins	8 -pin
Encoding	A-coded
Design	Angled

Cable properties

Number of conductors	4 Piece(s)
Shielded	No
Cable design	Interconnection cable
Cable length	300 mm

Environmental data

Certifications

Classification

Customs tariff number	85444290
eCl@ss 8.0	27279218
eCl@ss 9.0	27060311
ETIM 5.0	EC001855
ETIM 6.0	EC001855

Electrical connection

Connection 1	
Type of connection	Connector
Thread size	M12
Type	Female
No. of pins	4 -pin
Encoding	A-coded
Design	Axial

Part no.: 150756 – CB-M12-CC12 – Interconnection cable

Connection 2	
Type of connection	Connector
Thread size	M12
Type	Male
Handle body material	
No. of pins	8 -pin
Encoding	A-coded
Design	Angled
Lock	