


## Technical data sheet Interconnection cable

Part no.: 50130488

KDS CR-SUB-9A-RJ41-A-T0-024-C

### Contents

- Technical data
- Electrical connection

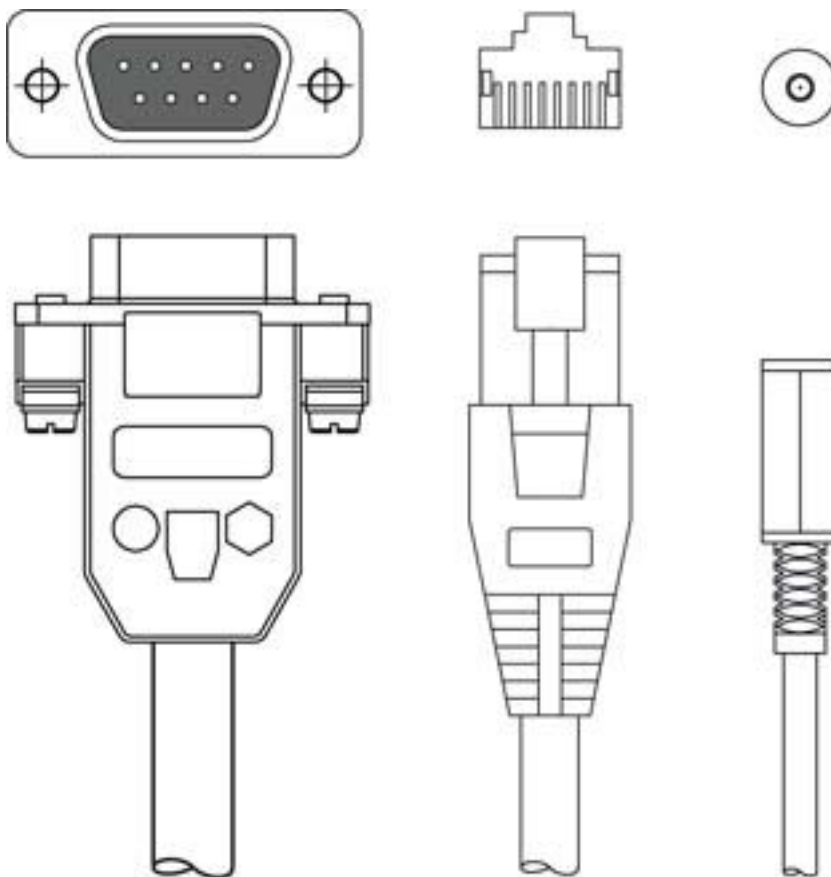

For illustration purposes only

## Technical data

### Basic data

|                        |                                        |
|------------------------|----------------------------------------|
| Suitable for           | HCR 6200 series mobile 2D-code readers |
| Suitable for interface | RS 232                                 |
|                        | TTL                                    |

### Connection

#### Connection 1

|                    |        |
|--------------------|--------|
| Type of connection | Sub-D  |
| Type               | Female |
| No. of pins        | 9 -pin |
| Version            | Axial  |

#### Connection 2

|                    |      |
|--------------------|------|
| Type of connection | RJ41 |
|--------------------|------|

#### Connection 3

|                    |           |
|--------------------|-----------|
| Type of connection | Connector |
| Thread size        | Pluggable |
| Type               | Female    |
| No. of pins        | 2 -pin    |
| Version            | Axial     |

#### Cable properties

|                             |             |
|-----------------------------|-------------|
| Number of conductors        | 9 Piece(s)  |
| Sheathing color             | Black       |
| Shielded                    | Yes         |
| Cable design                | Helix cable |
| Cable diameter (external)   | 5 mm        |
| Cable length                | 2,400 mm    |
| Sheathing material          | PVC         |
| Suitability for drag chains | No          |

### Mechanical data

|            |       |
|------------|-------|
| Net weight | 115 g |
|------------|-------|

### Classification

|                       |          |
|-----------------------|----------|
| Customs tariff number | 85444290 |
| ECLASS 5.1.4          | 27279201 |
| ECLASS 8.0            | 27279218 |
| ECLASS 9.0            | 27060311 |
| ECLASS 10.0           | 27060311 |
| ECLASS 11.0           | 27060311 |
| ECLASS 12.0           | 27060311 |
| ECLASS 13.0           | 27060311 |
| ECLASS 14.0           | 27060311 |
| ECLASS 15.0           | 27060311 |
| ECLASS 16.0           | 27060311 |
| ETIM 5.0              | EC001855 |
| ETIM 6.0              | EC001855 |
| ETIM 7.0              | EC001855 |
| ETIM 8.0              | EC001855 |
| ETIM 9.0              | EC001855 |
| ETIM 10.0             | EC001855 |

## Electrical connection

### Connection 1

|                    |        |
|--------------------|--------|
| Type of connection | Sub-D  |
| Type               | Female |
| No. of pins        | 9 -pin |
| Version            | Axial  |

### Connection 2

|                    |      |
|--------------------|------|
| Type of connection | RJ41 |
|--------------------|------|

### Connection 3

|                    |           |
|--------------------|-----------|
| Type of connection | Connector |
| Thread size        | Pluggable |
| Type               | Female    |
| No. of pins        | 2 -pin    |
| Version            | Axial     |