



## Technical data sheet Interconnection cable

Part no.: 50035355

KB 031-3000

### Contents

 - Technical data
- Electrical connection

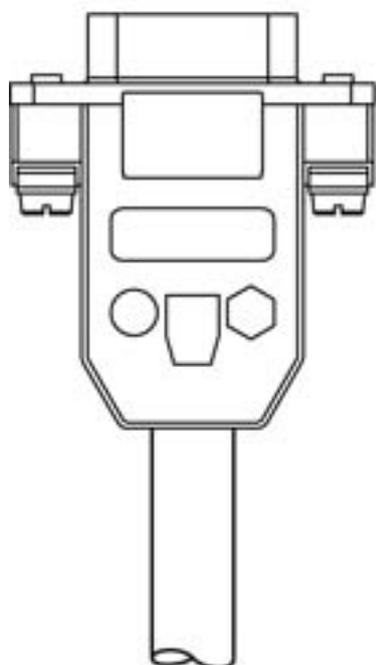

For illustration purposes only



## Technical data

### Basic data

Suitable for interface	RS 232
	RS 485

### Electrical data

#### Performance data

Operating voltage	30 V AC/DC
-------------------	------------

### Connection

#### Connection 1

Type of connection	Sub-D
Connector, LED	No
Type	Female
No. of pins	15 -pin
Version	Axial

#### Connection 2

Type of connection	JST ZHR connector
No. of pins	16 -pin

#### Cable properties

Number of conductors	16 Piece(s)
Sheathing color	Black
Shielded	Yes
Cable design	Connection cable (open on one end)
Cable diameter (external)	8.1 mm
Cable length	3,000 mm
Wire insulation	PVC
Suitability for drag chains	No

### Mechanical data

Net weight	303 g
------------	-------

### Operation and display

#### Classification

Customs tariff number	85444290
ECLASS 5.1.4	27279201
ECLASS 8.0	27279218
ECLASS 9.0	27060311
ECLASS 10.0	27060311
ECLASS 11.0	27060311
ECLASS 12.0	27060311
ECLASS 13.0	27060311
ECLASS 14.0	27060311
ECLASS 15.0	27060311
ECLASS 16.0	27060311
ETIM 5.0	EC001855
ETIM 6.0	EC001855
ETIM 7.0	EC001855
ETIM 8.0	EC001855
ETIM 9.0	EC001855
ETIM 10.0	EC001855

## Electrical connection

### Connection 1

Type of connection	Sub-D
Connector, LED	No
Type	Female
No. of pins	15 -pin
Version	Axial

### Connection 2

Type of connection	JST ZHR connector
No. of pins	16 -pin