

## Technical data sheet


### Connection cable

Part no.: 50040579

KB-008-3000-YB

#### Contents

- Technical data
- Electrical connection
- Circuit diagrams

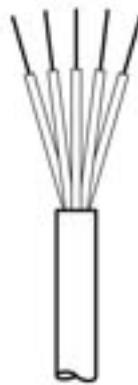

For illustration purposes only

## Technical data

### Connection

#### Connection 1

Type of connection	Connector
Thread size	M12
Type	Female
No. of pins	5 -pin
Encoding	A-coded
Version	Axial

#### Connection 2

Type of connection	Open end
--------------------	----------

#### Connection 3

Type of connection	Open end
--------------------	----------

#### Cable properties

Number of conductors	5 Piece(s)
Sheathing color	Black
Shielded	No
Cable design	Connection cable (open on one end)
Cable diameter (external)	5 mm
Cable length	3,000 mm
Sheathing material	PUR
Suitability for drag chains	No

### Mechanical data

Net weight	232 g
------------	-------

#### Classification

Customs tariff number	85444290
ECLASS 5.1.4	27279201
ECLASS 8.0	27279218
ECLASS 9.0	27060311
ECLASS 10.0	27060311
ECLASS 11.0	27060311
ECLASS 12.0	27060311
ECLASS 13.0	27060311
ECLASS 14.0	27060311
ECLASS 15.0	27060311
ECLASS 16.0	27060311
ETIM 5.0	EC001855
ETIM 6.0	EC001855
ETIM 7.0	EC001855
ETIM 8.0	EC001855
ETIM 9.0	EC001855
ETIM 10.0	EC001855

## Electrical connection

### Connection 1

Type of connection	Connector
Thread size	M12
Type	Female
No. of pins	5 -pin
Encoding	A-coded
Version	Axial

### Connection 2

Type of connection	Open end
--------------------	----------

### Connection 3

Type of connection	Open end
--------------------	----------

## Circuit diagrams

### Wiring schematic

