

Technical data sheet

Adapter

Part no.: 50134904

KDS U-M8-4A-M8-3A-P1-000

Contents

- Technical data
- Electrical connection
- Circuit diagrams
- Accessories



Figure can vary



Technical data

Electrical data

Performance data

Operating voltage Max. 50 V AC / 60 V DC

Connection

Connection 1

Type of connection Connector

Thread size M8

Type Female

No. of pins 4 -pin

Version Axial

Connection 2

Type of connection Connector

Thread size M8

Type Male

No. of pins 3 -pin

Version Axial

Cable properties

Shielded No

Mechanical data

Width across flats 9 mm

Material PUR

Certifications

Degree of protection IP 67

Classification

Customs tariff number 85366990

ECLASS 5.1.4 27279201

ECLASS 8.0 27440104

ECLASS 9.0 27069190

ECLASS 10.0 27440106

ECLASS 11.0 27440106

ECLASS 12.0 27440106

ECLASS 13.0 27440106

ETIM 5.0 EC002498

ETIM 6.0 EC002498

ETIM 7.0 EC002925

ETIM 8.0 EC002925

Electrical connection

Connection 1

Type of connection Connector

Thread size M8

Type Female

No. of pins 4 -pin

Version Axial

Connection 2

Type of connection Connector


Thread size M8

Type Male

No. of pins 3 -pin


Version Axial

Circuit diagrams

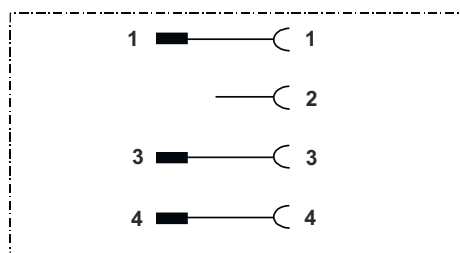

Accessories

General

	Part no.	Designation	Article	Description
	50132266	TT-Set 0,6-13	Tool	Type: Torque key Width across flats: 13 mm Torque: 0.6 N·m Material: Plastic, Stainless steel Ambient temperature: -40 ... 120 °C

Note



A list with all available accessories can be found on the Leuze website in the Download tab of the article detailed page.