

Technical data sheet

Adapter

Part no.: 50134904

KDS U-M8-4A-M8-3A-P1-000

Contents

- Technical data
- Electrical connection
- Circuit diagrams
- Accessories



Figure can vary



Technical data

Electrical data

Performance data

Operating voltage Max. 50 V AC / 60 V DC

Connection

Connection 1

Type of connection Connector

Thread size M8

Type Female

No. of pins 4 -pin

Version Axial

Connection 2

Type of connection Connector

Thread size M8

Type Male

No. of pins 3 -pin

Version Axial

Cable properties

Shielded No

Mechanical data

Width across flats 9 mm

Material PUR

Certifications

Degree of protection IP 67

Classification

Customs tariff number 85366990

eCl@ss 5.1.4 27279201

eCl@ss 8.0 27440104

eCl@ss 9.0 27069190

eCl@ss 10.0 27440106

eCl@ss 11.0 27440106

ETIM 5.0 EC002498

ETIM 6.0 EC002498

ETIM 7.0 EC002925

Electrical connection

Connection 1

Type of connection Connector

Thread size M8

Type Female

No. of pins 4 -pin

Version Axial

Connection 2

Type of connection Connector


Thread size M8

Type Male

No. of pins 3 -pin


Version Axial

Circuit diagrams

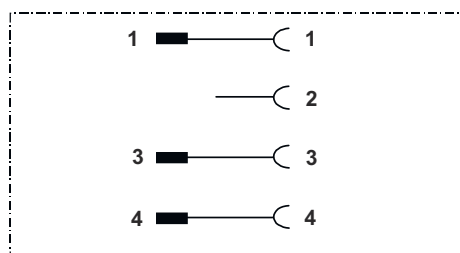

Accessories

General

	Part no.	Designation	Article	Description
	50132266	TT-Set 0,6-13	Tool	Type: Torque key Width across flats: 13 mm Torque: 0.6 N·m Material: Plastic, Stainless steel Ambient temperature: -40 ... 120 °C

Note



A list with all available accessories can be found on the Leuze website in the Download tab of the article detailed page.