

Technical data sheet

Connection cable

Part no.: 50137269

KD S-M30-30A-V1-050

Contents

- Technical data
- Electrical connection

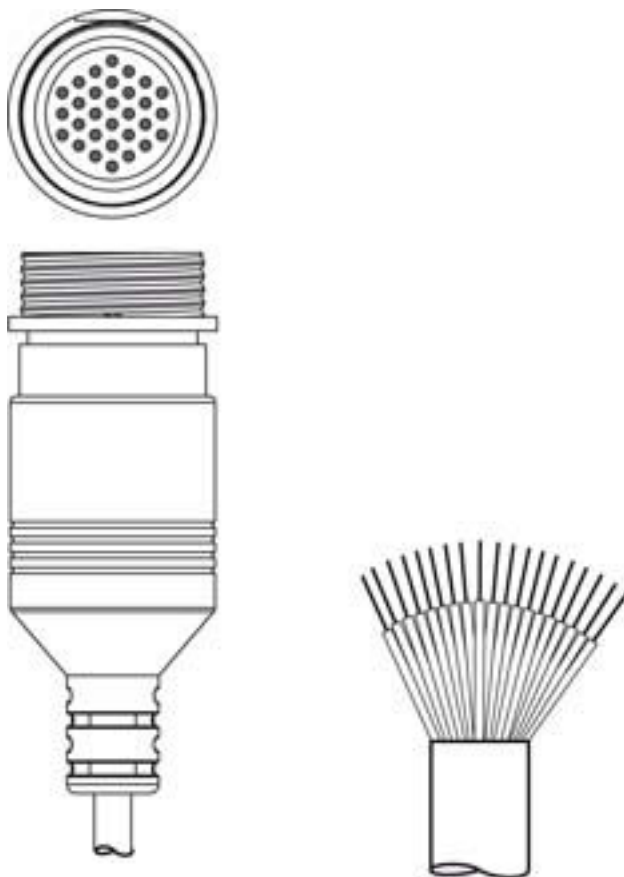


Figure can vary

Technical data

Connection

Connection 1

Type of connection	Connector
Thread size	M30
Type	Female
No. of pins	30 -pin
Version	Axial

Connection 2

Type of connection	Open end
--------------------	----------

Cable properties

Number of conductors	30 Piece(s)
Sheathing color	Black
Shielded	Yes
Cable design	Connection cable (open on one end)
Cable diameter (external)	9 mm
Cable length	5,000 mm
Sheathing material	PVC
Suitability for drag chains	No

Certifications

Certifications	RoHS
----------------	------

Classification

Customs tariff number	85444290
eCl@ss 5.1.4	27279201
eCl@ss 8.0	27279218
eCl@ss 9.0	27060311
eCl@ss 10.0	27060311
eCl@ss 11.0	27060311
ETIM 5.0	EC001855
ETIM 6.0	EC001855
ETIM 7.0	EC001855

Electrical connection


Connection 1

Type of connection	Connector
Thread size	M30
Type	Female
No. of pins	30 -pin
Version	Axial
Connector housing	Shield

Pin

Conductor color

1	White
2	Brown
3	Green
4	Gray
5	Pink
6	Red
7	Yellow
8	Black
9	Violet
10	Gray / Pink
11	Blue / Red
12	Green / White
13	Brown / Green
14	White / Yellow
15	Brown / Yellow
16	Gray / White
17	Brown / Gray
18	Pink / White
19	Brown / Pink
20	Blue / White
21	Blue / Brown
22	Red / White
23	Brown / Red
24	Black / White

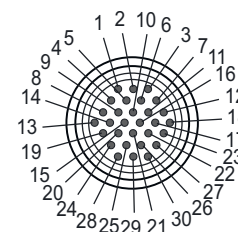

Electrical connection

Pin	Conductor color
25	Black / Brown
26	Gray / Yellow
27	Green / Pink
28	-
29	Blue
30	Gray / Green

Connection 2

Type of connection	Open end
--------------------	----------