

Technical data sheet Interconnection cable

Part no.: 50113396

KB DSub-9P-3000

Contents

- Technical data
- Electrical connection

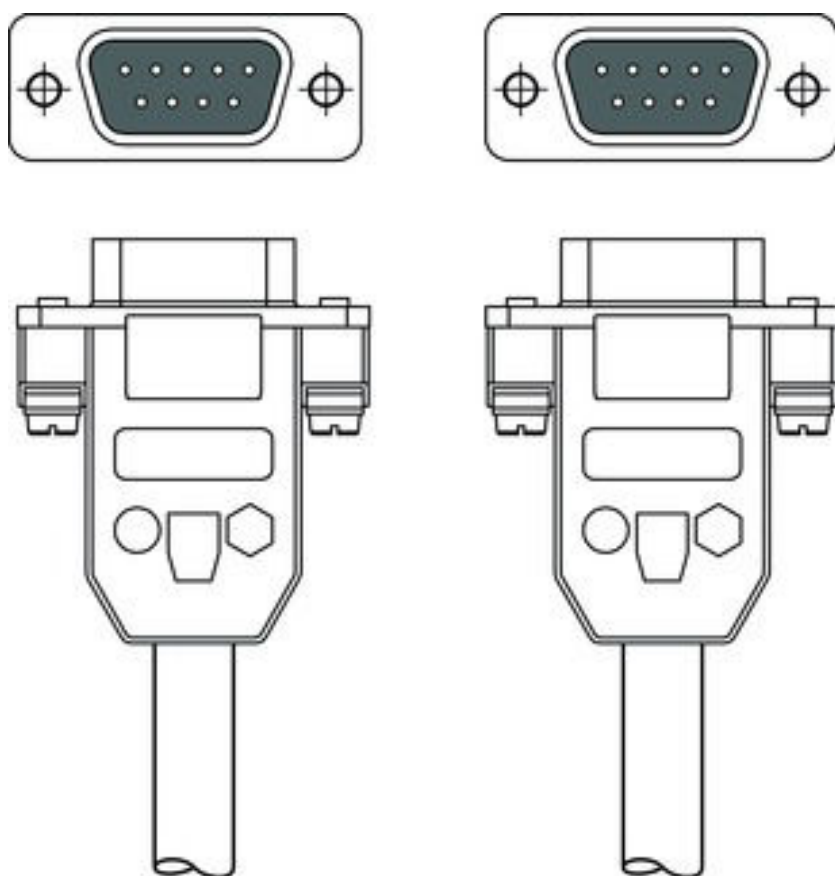


Figure can vary



Technical data

Basic data

Suitable for interface	RS 232
------------------------	--------

Connection

Connection 1

Function	Data interface
Type of connection	Sub-D
Type	Female
No. of pins	9 -pin
Version	Axial

Connection 2

Function	Data interface
Type of connection	Sub-D
Type	Female
No. of pins	9 -pin
Version	Axial

Cable properties

Number of conductors	8 Piece(s)
Sheathing color	Gray
Shielded	Yes
Cable design	Interconnection cable
Cable diameter (external)	6 mm
Cable length	3,000 mm
Sheathing material	PVC
Suitability for drag chains	No

Classification

Customs tariff number	85444290
eCl@ss 5.1.4	27279201
eCl@ss 8.0	27279218
eCl@ss 9.0	27060311
eCl@ss 10.0	27060311
eCl@ss 11.0	27060311
ETIM 5.0	EC001855
ETIM 6.0	EC001855
ETIM 7.0	EC001855


Electrical connection

Connection 1

Function	Data interface
Type of connection	Sub-D
Type	Female
No. of pins	9 -pin
Version	Axial

Pin Pin assignment

1	DCD
2	RxD
3	TXD
4	DTR
5	GND
6	n.c.
7	RTS
8	CTS
9	RI

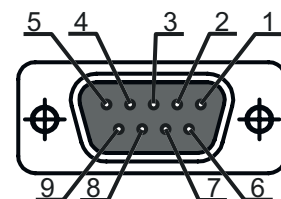

Connection 2

Function	Data interface
Type of connection	Sub-D
Type	Female
No. of pins	9 -pin
Version	Axial

Electrical connection

Pin	Pin assignment
1	DTR
2	TXD
3	RxD
4	DCD
5	GND
6	n.c.
7	CTS
8	RTS
9	RI

