

## Technical data sheet

### Deflecting mirror

Part no.: 529615

UM60-1500

#### Contents

- Technical data
- Dimensioned drawings



For illustration purposes only

## Technical data

### Basic data

|                           |                                    |
|---------------------------|------------------------------------|
| Series                    | UM                                 |
| Type, columns and mirrors | Deflecting mirror on the rear side |

### Mechanical data

|                              |                                        |
|------------------------------|----------------------------------------|
| Dimension (W x H x L)        | 25 mm x 68 mm x 1,570 mm               |
| Net weight                   | 2,820 g                                |
| Housing color                | Yellow, RAL 1021                       |
| Type of fastening            | Groove mounting<br>Swivel mount        |
| Suitable for sensor          | MLC 500, MLC 300 safety light curtains |
| Protected field height up to | 1,500 mm                               |
| Mirror length                | 1,560 mm                               |


### Classification

|                       |          |
|-----------------------|----------|
| Customs tariff number | 70099200 |
| ECLASS 5.1.4          | 27279207 |
| ECLASS 8.0            | 27279207 |
| ECLASS 9.0            | 27273605 |
| ECLASS 10.0           | 27273605 |
| ECLASS 11.0           | 27273605 |
| ECLASS 12.0           | 27273605 |
| ECLASS 13.0           | 27273605 |
| ECLASS 14.0           | 27273605 |
| ECLASS 15.0           | 27273605 |
| ECLASS 16.0           | 27273605 |
| ETIM 5.0              | EC002467 |
| ETIM 6.0              | EC002467 |
| ETIM 7.0              | EC002467 |
| ETIM 8.0              | EC002467 |
| ETIM 9.0              | EC002467 |
| ETIM 10.0             | EC002467 |

## Dimensioned drawings


All dimensions in millimeters

### Mirror

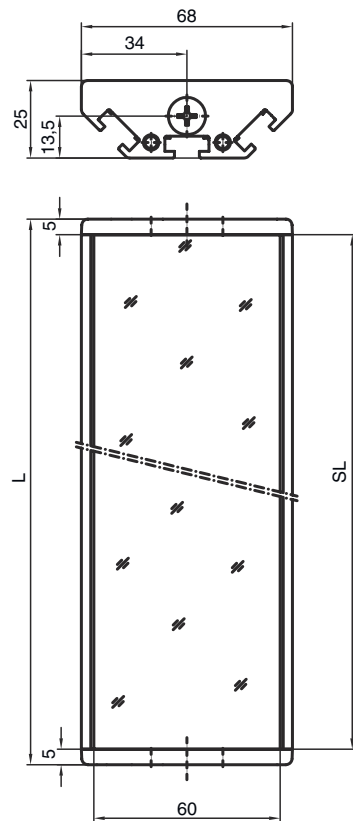


L Length = 1570 mm  
SL Mirror length = 1560 mm

### Mounting distances

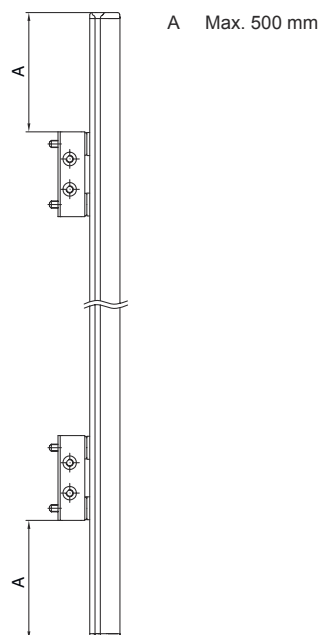

## Dimensioned drawings


Mounting with BT-UM60 standard bracket

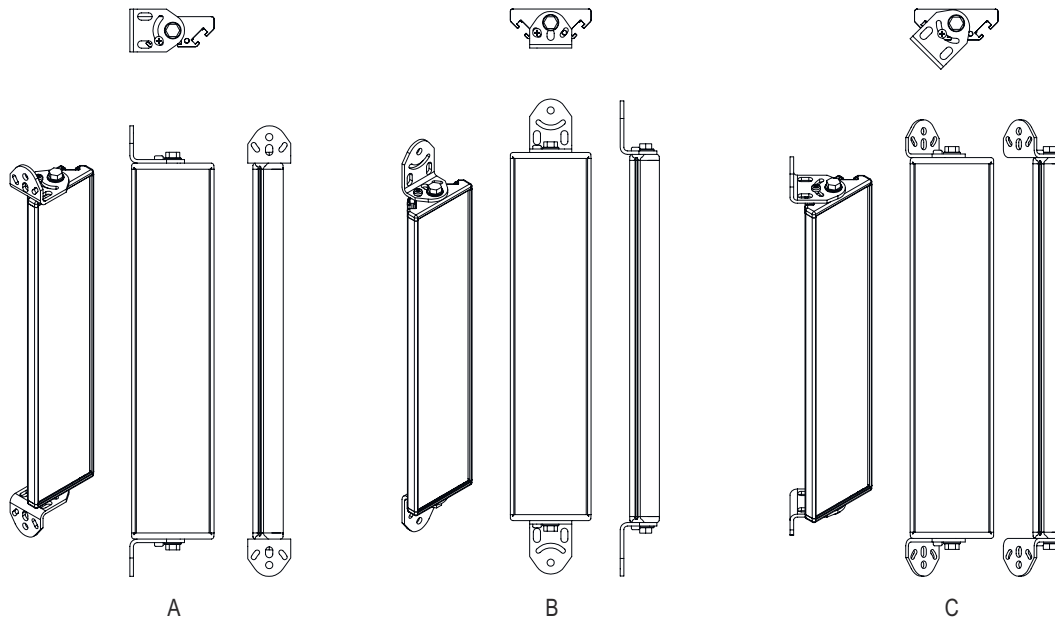


- A Lateral
- B Rear side
- C Adjustable at an angle (0 - 90°)

## Dimensioned drawings

 Mounting with BT-SSD swiveling mounting bracket



A

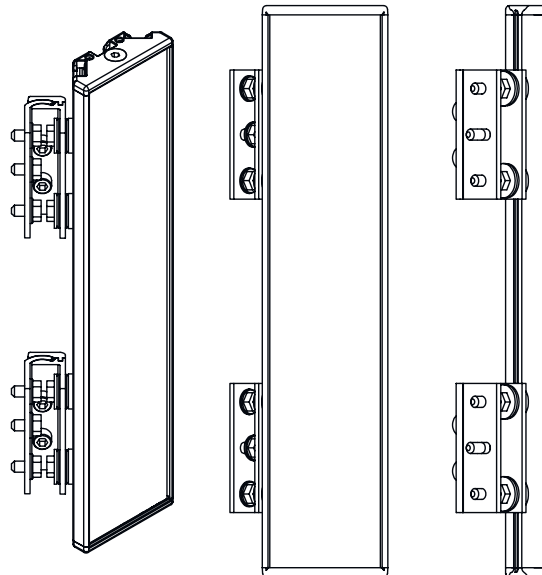

B

- A Rear side
- B Lateral 45°