

Technical data sheet

Interconnection cable

Part no.: 548362
CB-M12-2000-5GF/GM

Contents

- Technical data
- Electrical connection

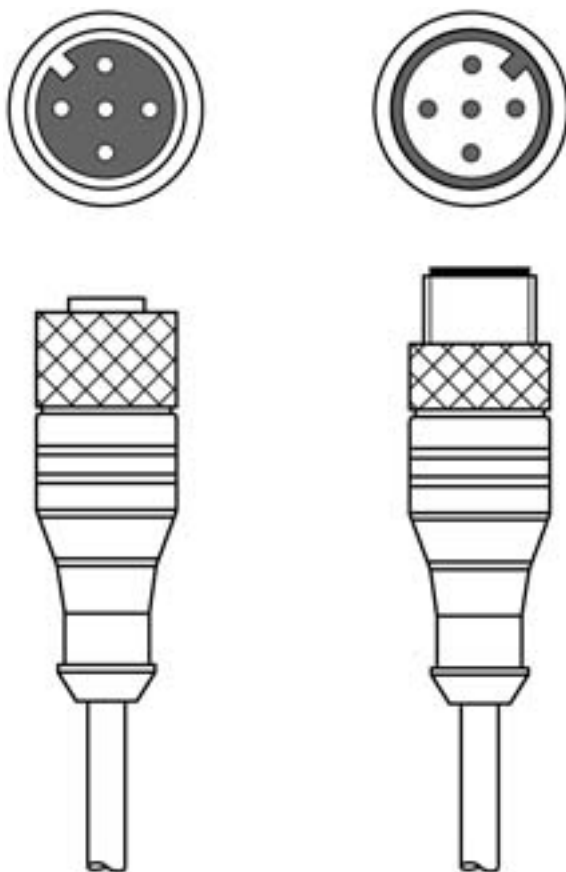


Figure can vary



Technical data

Electrical data

Connection

Connection 1

Type of connection	Connector
Thread size	M12
Type	Female
No. of pins	5 -pin
Encoding	A-coded
Design	Axial

Connection 2

Type of connection	Connector
Thread size	M12
Type	Male
No. of pins	5 -pin
Encoding	A-coded
Design	Axial

Cable properties

Number of conductors	5 Piece(s)
Wire cross section	0.5 mm ²
Sheathing color	Black
Shielded	No
Cable design	Interconnection cable
Cable diameter (external)	5.4 mm
Cable length	2,000 mm
Conductor material	Copper
Sheathing material	PUR

Environmental data

Ambient temperature, operation, stationary use	-25 ... 50 °C
--	---------------

Certifications

Certifications	c UL
	UL

Classification

Customs tariff number	85444290
eCl@ss 8.0	27279218
eCl@ss 9.0	27060311
ETIM 5.0	EC001855
ETIM 6.0	EC001855

Electrical connection

Connection 1

Type of connection	Connector
Thread size	M12
Type	Female
No. of pins	5 -pin
Encoding	A-coded
Design	Axial

Connection 2

Type of connection	Connector
Thread size	M12
Type	Male
No. of pins	5 -pin
Encoding	A-coded
Design	Axial