

Technical data sheet Interconnection cable

Part no.: 548100

CB-M12-25000S-4GF/GM

Contents

- Technical data
- Electrical connection

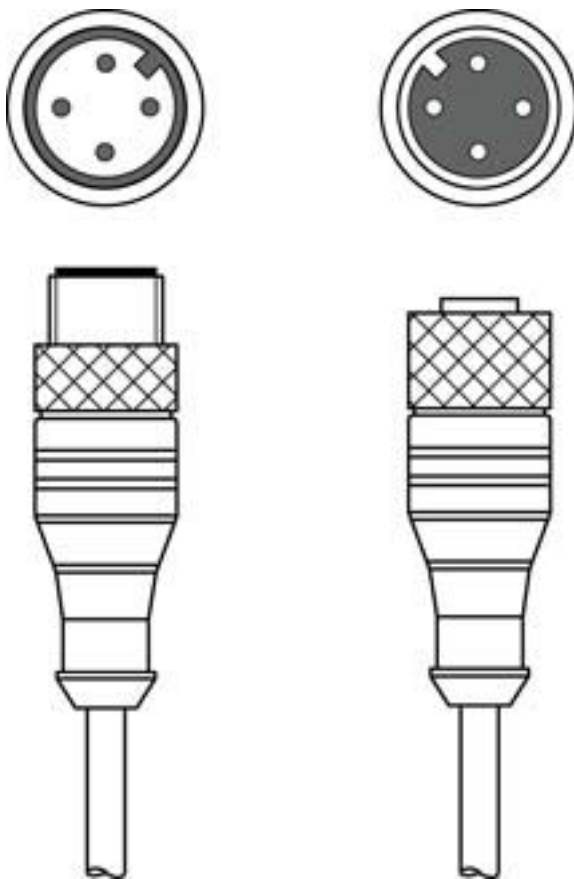


Figure can vary



Technical data

Connection

Connection 1

Type of connection	Connector
Thread size	M12
Type	Female
Handle body material	TPU
No. of pins	4 -pin
Encoding	A-coded
Design	Axial
Operating current per contact	4 A

Connection 2

Type of connection	Connector
Thread size	M12
Type	Male
Handle body material	TPU
No. of pins	4 -pin
Encoding	A-coded
Design	Axial
Operating current per contact	4 A

Cable properties

Number of conductors	4 Piece(s)
Sheathing color	Black
Shielded	Yes
Cable design	Interconnection cable
Cable length	25,000 mm
Sheathing material	PUR

Classification

Customs tariff number	85444290
eCl@ss 8.0	27279218
eCl@ss 9.0	27060311
ETIM 5.0	EC001855
ETIM 6.0	EC001855

Electrical connection

Connection 1

Type of connection	Connector
Thread size	M12
Type	Female
Handle body material	TPU
No. of pins	4 -pin
Encoding	A-coded
Design	Axial
Operating current per contact	4 A

Connection 2

Type of connection	Connector
Thread size	M12
Type	Male
Handle body material	TPU
No. of pins	4 -pin
Encoding	A-coded
Design	Axial
Operating current per contact	4 A