

## Technical data sheet Interconnection cable

Part no.: 50138353

KDS HS-SUB-9A-RJ41-AA-T1-028

### Contents

- Technical data
- Electrical connection

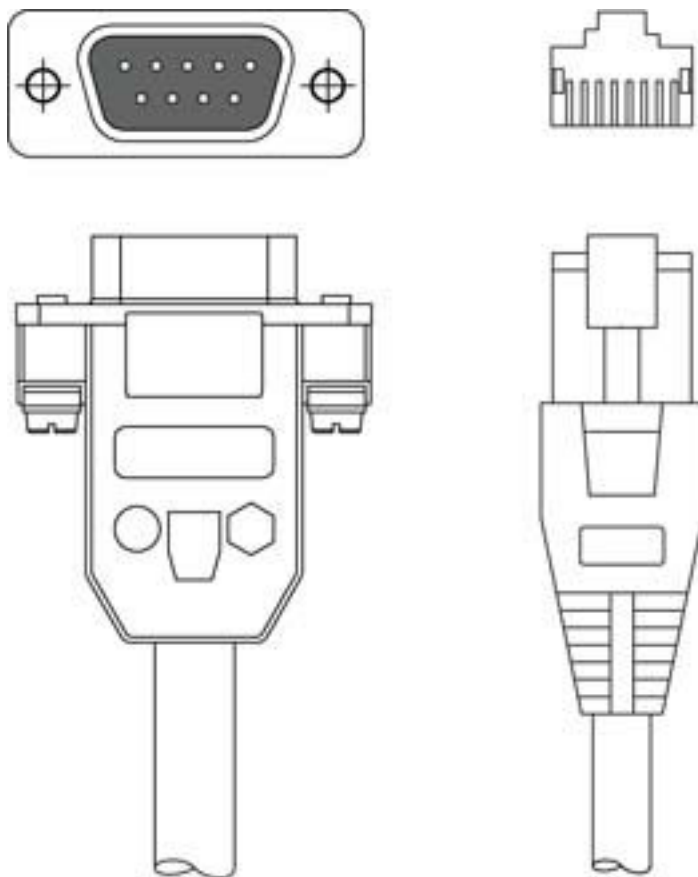


Figure can vary

## Technical data

### Basic data

Suitable for	HS 66x8
Suitable for interface	RS 232

### Connection

#### Connection 1

Type of connection	RJ41
--------------------	------

#### Connection 2

Type of connection	Sub-D
Type	Female
No. of pins	9 -pin
Version	Axial

#### Cable properties

Number of conductors	6 Piece(s)
Sheathing color	Black
Shielded	Yes
Cable design	Helix cable
Cable diameter (external)	6 mm
Cable length	2,800 mm
Sheathing material	TPE
Suitability for drag chains	No

### Classification

Customs tariff number	85444290
eCl@ss 5.1.4	27279201
eCl@ss 8.0	27279218
eCl@ss 9.0	27060311
eCl@ss 10.0	27060311
eCl@ss 11.0	27060311
ETIM 5.0	EC001855
ETIM 6.0	EC001855
ETIM 7.0	EC001855


## Electrical connection

### Connection 1

Type of connection	RJ41
--------------------	------

#### Pin Pin assignment

1	Cable ID
2	+5 V DC
3	GND
4	TxD RS 232
5	RxD RS232
6	RTS RS 232
7	CTS RS 232
8	n.c.
9	n.c.
10	+12 V DC

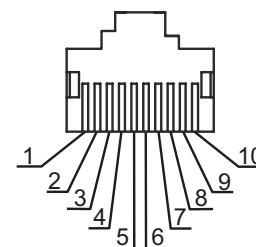

### Connection 2

Type of connection	Sub-D
Type	Female
No. of pins	9 -pin
Version	Axial

## Electrical connection

Pin	Pin assignment
1	Shield
2	TXD
3	RxD
4	n.c.
5	GND
6	n.c.
7	CTS
8	RTS
9	+5 V DC

