

Technical data sheet Interconnection cable

Part no.: 50138358

KY-HS-DDS-D9AJ2ARAA-020-T1

Contents

- Technical data
- Electrical connection

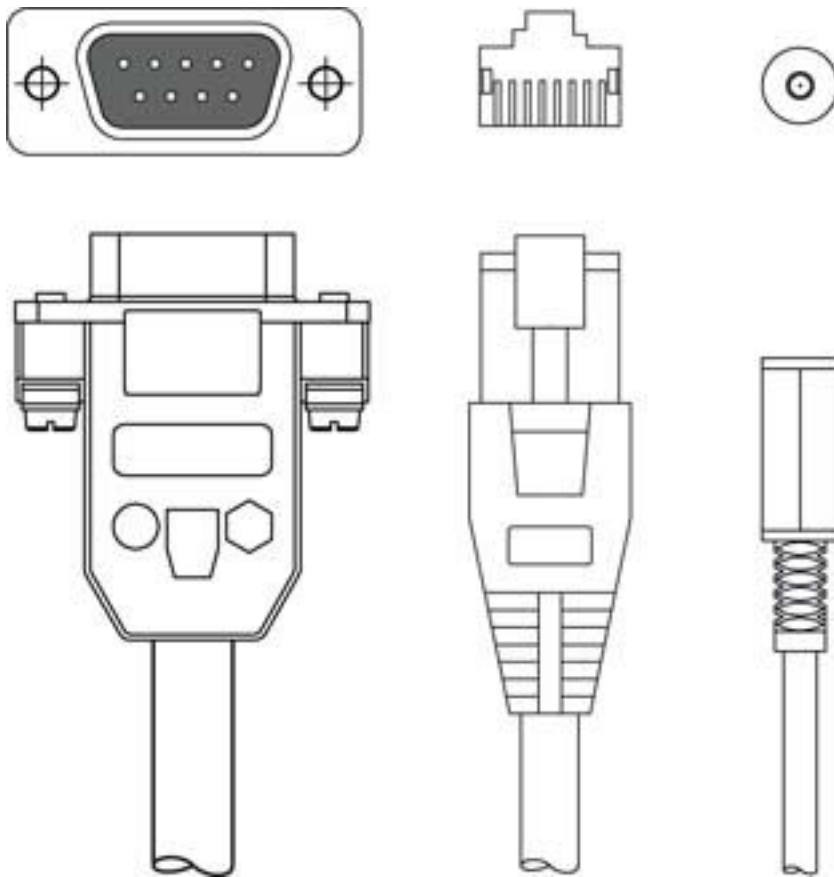


Figure can vary

Technical data

Basic data

Suitable for	HS 66x8
Suitable for interface	RS 232

Connection

Connection 1

Type of connection	RJ41
--------------------	------

Connection 2

Type of connection	Sub-D
Type	Female
No. of pins	9 -pin
Version	Axial

Connection 3

Type of connection	Connector
Thread size	Pluggable
Type	Female
No. of pins	2 -pin
Version	Axial

Cable properties

Number of conductors	6 Piece(s)
Sheathing color	Black
Shielded	Yes
Cable diameter (external)	6 mm
Cable length	2,000 mm
Sheathing material	TPU
Suitability for drag chains	No

Classification

Customs tariff number	85444290
eCl@ss 5.1.4	27279201
eCl@ss 8.0	27279218
eCl@ss 9.0	27060311
eCl@ss 10.0	27060311
eCl@ss 11.0	27060311
ETIM 5.0	EC001855
ETIM 6.0	EC001855
ETIM 7.0	EC001855


Electrical connection

Connection 1

Type of connection	RJ41
--------------------	------

Pin Pin assignment

1	Cable ID
2	+5 V DC
3	GND
4	TxD RS 232
5	RxD RS232
6	RTS RS 232
7	CTS RS 232
8	n.c.
9	n.c.
10	+12 V DC

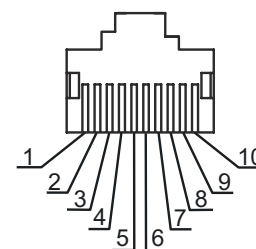


Connection 2

Type of connection	Sub-D
Type	Female
No. of pins	9 -pin
Version	Axial

Pin Pin assignment

1	Shield
2	TXD
3	RxD
4	n.c.
5	GND
6	n.c.
7	CTS
8	RTS
9	n.c.

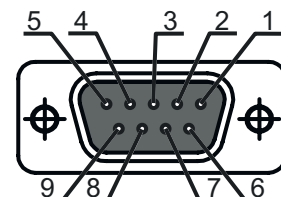

Electrical connection

Connection 3

Type of connection	Connector
Thread size	Pluggable
Type	Female
No. of pins	2 -pin
Version	Axial