


## Technical data sheet Interconnection cable

Part no.: 50129781

KDS DN-M12-5A-M12-5A-P3-050

### Contents

- Technical data
- Electrical connection
- Circuit diagrams

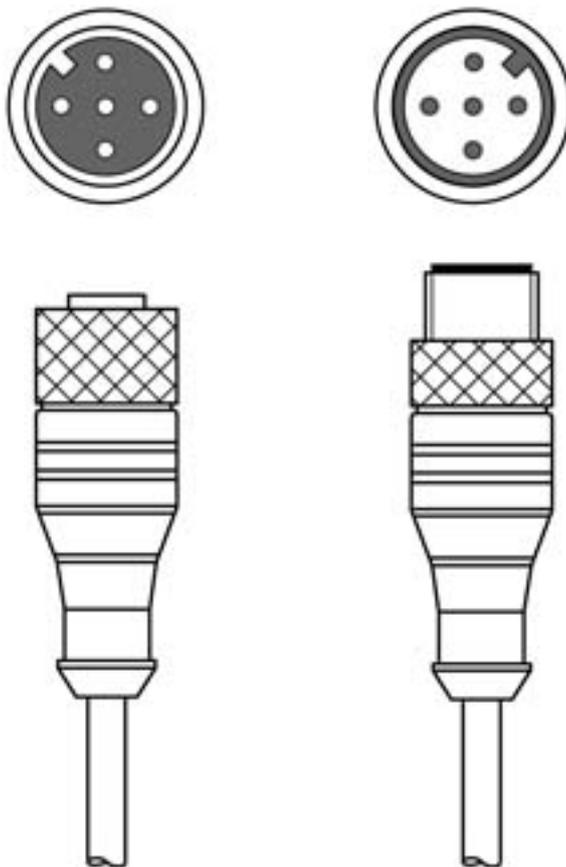

For illustration purposes only



## Technical data

### Basic data

Application	Oil and lubricant resistant
Suitable for interface	CANopen DeviceNet

### Connection

#### Connection 1

Type of connection	Connector
Thread size	M12
Type	Female
No. of pins	5 -pin
Encoding	A-coded
Version	Axial
Connector, LED	No

#### Connection 2

Type of connection	Connector
Thread size	M12
Type	Male
No. of pins	5 -pin
Encoding	A-coded
Version	Axial

#### Cable properties

Number of conductors	4 Piece(s)
Sheathing color	Violet
Shielded	Yes
Silicone-free	Yes
Cable design	Interconnection cable
Cable diameter (external)	7 mm
Cable length	5,000 mm
Sheathing material	PUR
Suitability for drag chains	No

### Mechanical data

Width across flats	13 mm
Net weight	279 g

### Operation and display

#### Classification

Customs tariff number	85444290
ECLASS 5.1.4	27279201
ECLASS 8.0	27279218
ECLASS 9.0	27060311
ECLASS 10.0	27060311
ECLASS 11.0	27060311
ECLASS 12.0	27060311
ECLASS 13.0	27060311
ECLASS 14.0	27060311
ECLASS 15.0	27060311
ECLASS 16.0	27060311
ETIM 5.0	EC001855
ETIM 6.0	EC001855
ETIM 7.0	EC001855
ETIM 8.0	EC001855
ETIM 9.0	EC001855
ETIM 10.0	EC001855

## Electrical connection

### Connection 1

Type of connection	Connector
Thread size	M12
Type	Female
No. of pins	5 -pin
Encoding	A-coded
Version	Axial
Connector, LED	No

### Connection 2

Type of connection	Connector
Thread size	M12
Type	Male
No. of pins	5 -pin
Encoding	A-coded
Version	Axial

## Circuit diagrams

