

## Technical data sheet

### Service line

Part no.: 50110155

KB-Service-3000

#### Contents

- Technical data
- Electrical connection

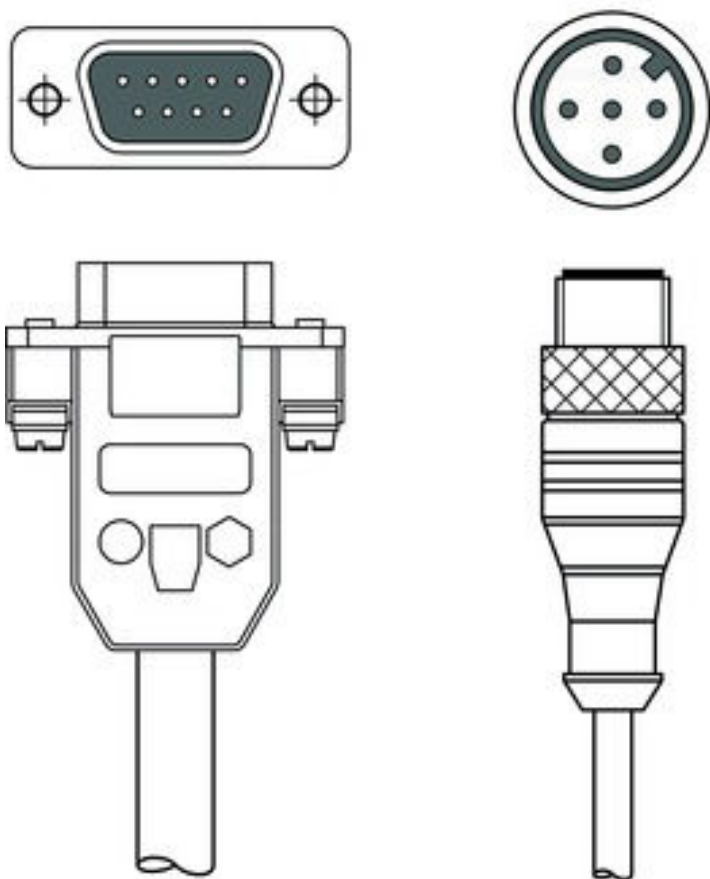


Figure can vary

## Technical data

### Connection

#### Connection 1

Type of connection	Connector
Thread size	M12
Type	Male
No. of pins	5 -pin
Encoding	A-coded
Version	Axial
Connector, LED	No

#### Connection 2

Type of connection	Sub-D
Type	Female
No. of pins	9 -pin
Version	Axial

#### Cable properties

Number of conductors	5 Piece(s)
Sheathing color	Black
Shielded	Yes
Cable design	Interconnection cable
Cable length	3,000 mm
Sheathing material	PVC
Suitability for drag chains	No

### Classification

Customs tariff number	85444290
ECLASS 5.1.4	27279201
ECLASS 8.0	27279218
ECLASS 9.0	27060311
ECLASS 10.0	27060313
ECLASS 11.0	27060313
ECLASS 12.0	27060313
ETIM 5.0	EC001855
ETIM 6.0	EC001855
ETIM 7.0	EC001855

## Electrical connection

### Connection 1

Type of connection	Connector
Thread size	M12
Type	Male
No. of pins	5 -pin
Encoding	A-coded
Version	Axial
Connector, LED	No

### Connection 2

Type of connection	Sub-D
Type	Female
No. of pins	9 -pin
Version	Axial