

Technical data sheet Interconnection cable

Part no.: 50106905

KB ET-30000-SSA

Contents

- Technical data
- Electrical connection

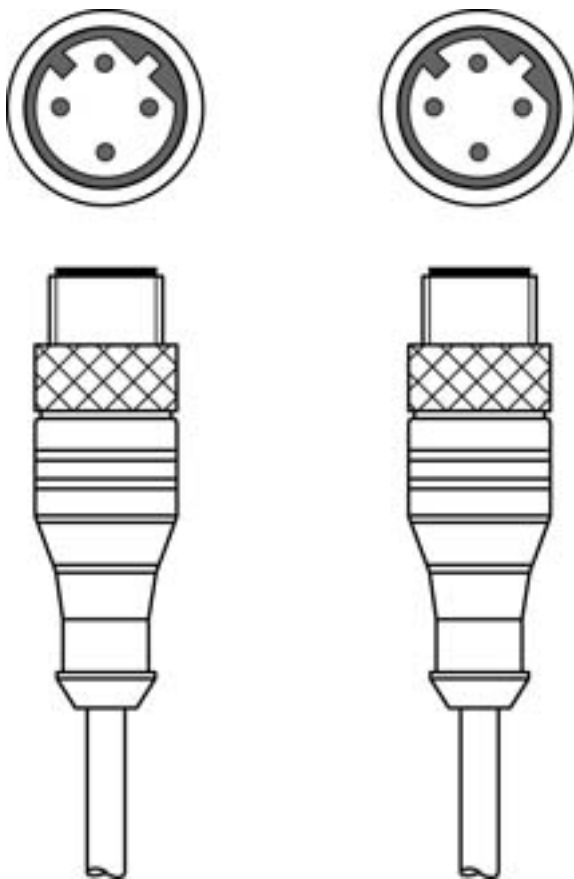


Figure can vary



Technical data

Basic data

Suitable for interface	Ethernet
------------------------	----------

Connection

Connection 1

Type of connection	Connector
Thread size	M12
Type	Male
No. of pins	4 -pin
Encoding	D-coded
Design	Axial

Connection 2

Type of connection	Connector
Thread size	M12
Type	Male
No. of pins	4 -pin
Encoding	D-coded
Design	Axial

Cable properties

Number of conductors	4 Piece(s)
Sheathing color	Green
Shielded	Yes
Cable design	Interconnection cable
Cable diameter (external)	6.5 mm
Cable length	30,000 mm
Sheathing material	PUR

Classification

Customs tariff number	85444290
eCl@ss 8.0	27279218
eCl@ss 9.0	27060311
ETIM 5.0	EC001855
ETIM 6.0	EC001855

Electrical connection

Connection 1

Type of connection	Connector
Thread size	M12
Type	Male
No. of pins	4 -pin
Encoding	D-coded
Design	Axial

Connection 2

Type of connection	Connector
Thread size	M12
Type	Male
No. of pins	4 -pin
Encoding	D-coded
Design	Axial