

Technical data sheet


Connection cable

Part no.: 50143055

KD PL-M12-5A-P0-150

Contents

- Technical data
- Electrical connection
- Circuit diagrams

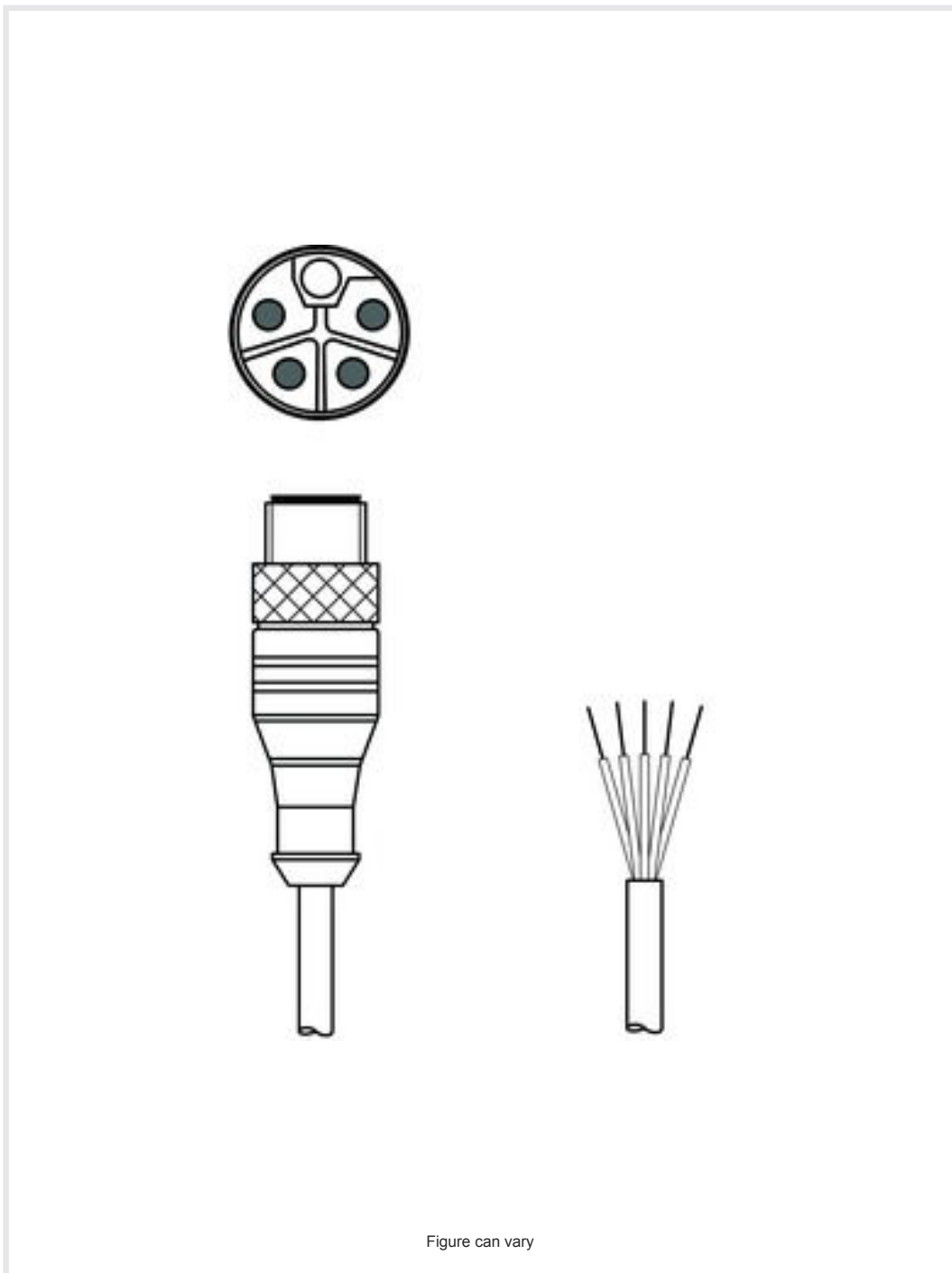

Technical data

Basic data

Suitable for	MD 748i
--------------	---------

Electrical data

Performance data

Operating voltage	50 V AC / 60 V DC
-------------------	-------------------

Connection

Connection 1

Type of connection	Connector
Thread size	M12
Type	Female
No. of pins	5 -pin
Encoding	L-coded
Version	Axial
Connector, LED	No

Cable properties

Number of conductors	5 Piece(s)
Wire cross section	1.5 mm ²
Sheathing color	Gray
Shielded	Yes
Cable design	Connection cable (open on one end)
Cable diameter (external)	8 mm
Cable length	15,000 mm
Sheathing material	PUR
Wire insulation	PP
Traverse rate	Max. 5 m/s with horiz. traverse path of 5m and and max. acceleration of 50m/s ²
Suitability for drag chains	Yes

Mechanical data

Bending cycles	10,000,000 Piece(s)
Bending radius, flexible laying, min.	Min. 7.5 x cable diameter
Bending radius, stationary laying, min.	Min. 4 x cable diameter

Operation and display

Environmental data

Ambient temperature, operation, flexible use	-30 ... 90 °C
Ambient temperature, operation, stationary use	-40 ... 90 °C

Certifications

Degree of protection	IP 65
	IP 67
	IP 69K
Certifications	c UL US

Classification

Customs tariff number	85444290
ECLASS 5.1.4	27279201
ECLASS 8.0	27279218
ECLASS 9.0	27060311
ECLASS 10.0	27060311
ECLASS 11.0	27060311
ECLASS 12.0	27060311
ETIM 5.0	EC001855
ETIM 6.0	EC001855
ETIM 7.0	EC001855
ETIM 8.0	EC001855

Electrical connection


Connection 1

Type of connection	Connector
Thread size	M12
Type	Female
No. of pins	5 -pin
Encoding	L-coded
Version	Axial
Connector, LED	No

Pin

Conductor color

1	Brown
2	White
3	Blue
4	Black
5	Gray

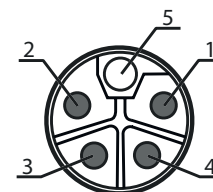

Circuit diagrams

Wiring schematic

