

Technical data sheet

Adapter cable

Part no.: 50104078

CB-ASM-PK1

Contents

- Technical data
- Electrical connection

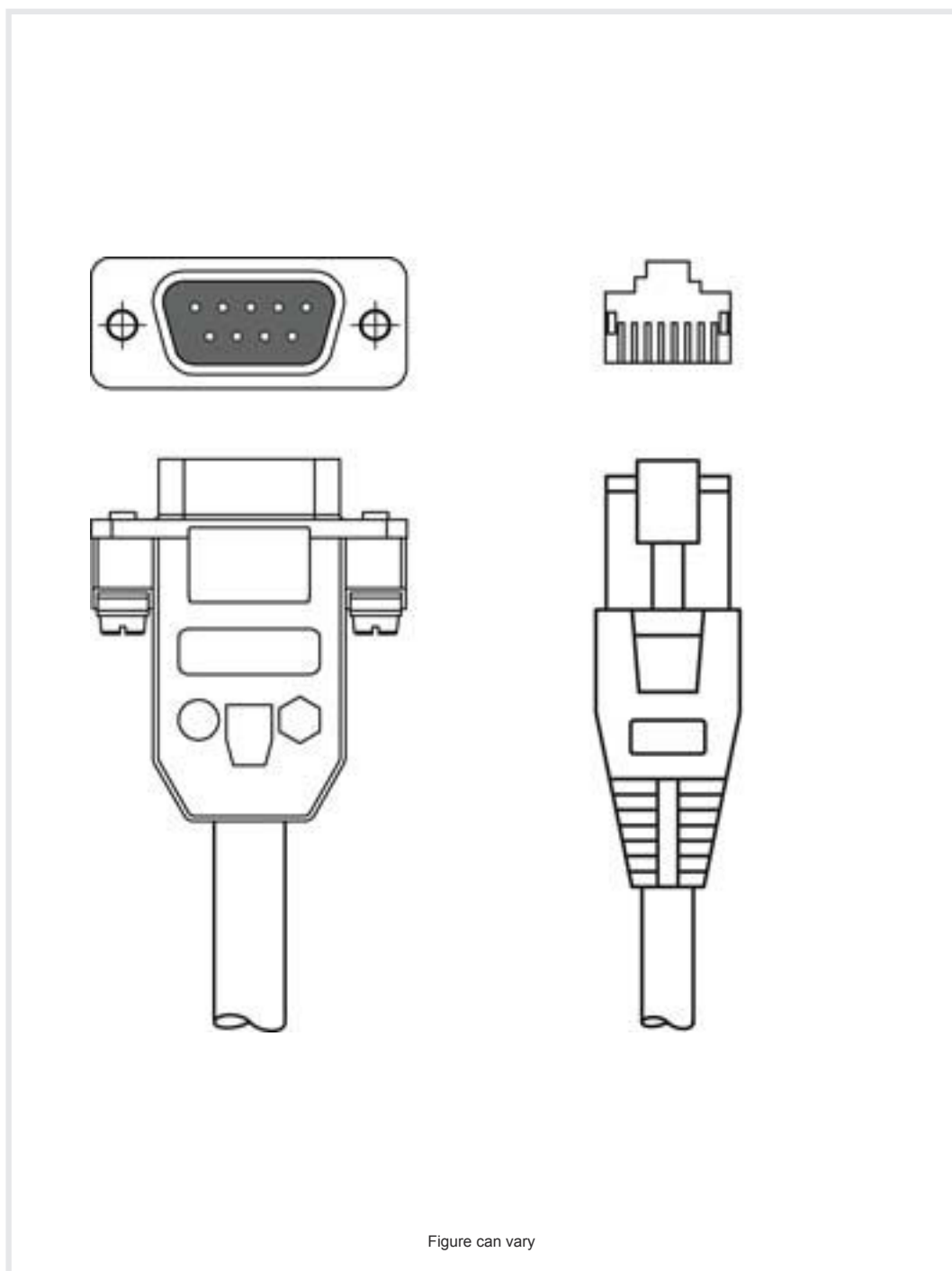


Figure can vary

Technical data

Electrical data

Performance data

Operating voltage	30 V AC/DC
-------------------	------------

Connection

Connection 1

Type of connection	Sub-D
Connector, LED	No
Type	Female
No. of pins	9 -pin
Version	Axial

Connection 2

Type of connection	RJ45
--------------------	------

Cable properties

Number of conductors	8 Piece(s)
Sheathing color	Gray
Shielded	No
Cable design	Interconnection cable
Cable length	2,500 mm
Sheathing material	PVC
Suitability for drag chains	No

Classification

Customs tariff number	85444290
ECLASS 5.1.4	27279201
ECLASS 8.0	27279218
ECLASS 9.0	27060311
ECLASS 10.0	27060313
ECLASS 11.0	27060313
ECLASS 12.0	27060313
ETIM 5.0	EC001855
ETIM 6.0	EC001855
ETIM 7.0	EC001855
ETIM 8.0	EC001855

Electrical connection

Connection 1

Type of connection	Sub-D
Connector, LED	No
Type	Female
No. of pins	9 -pin
Version	Axial

Connection 2

Type of connection	RJ45
--------------------	------