

Technical data sheet

Deflecting mirror

Part no.: 529609

UM60-900

Contents

- Technical data
- Dimensioned drawings



For illustration purposes only

Technical data

Basic data

Series	UM
Type, columns and mirrors	Deflecting mirror on the rear side

Mechanical data

Dimension (W x H x L)	25 mm x 68 mm x 970 mm
Net weight	1,720 g
Housing color	Yellow, RAL 1021
Type of fastening	Groove mounting Swivel mount
Suitable for sensor	MLC 500, MLC 300 safety light curtains
Protected field height up to	900 mm
Mirror length	960 mm


Classification

Customs tariff number	70099200
ECLASS 5.1.4	27279207
ECLASS 8.0	27279207
ECLASS 9.0	27273605
ECLASS 10.0	27273605
ECLASS 11.0	27273605
ECLASS 12.0	27273605
ECLASS 13.0	27273605
ECLASS 14.0	27273605
ECLASS 15.0	27273605
ETIM 5.0	EC002467
ETIM 6.0	EC002467
ETIM 7.0	EC002467
ETIM 8.0	EC002467
ETIM 9.0	EC002467
ETIM 10.0	EC002467


Dimensioned drawings

All dimensions in millimeters


Mirror

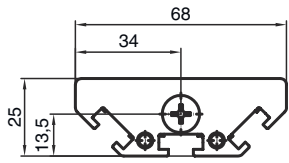

L Length = 970 mm
SL Mirror length = 960 mm

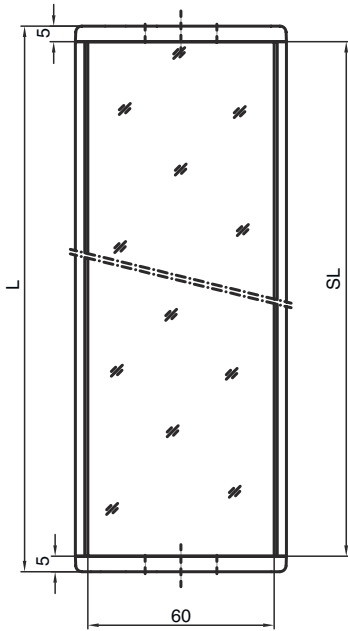


Mounting distances

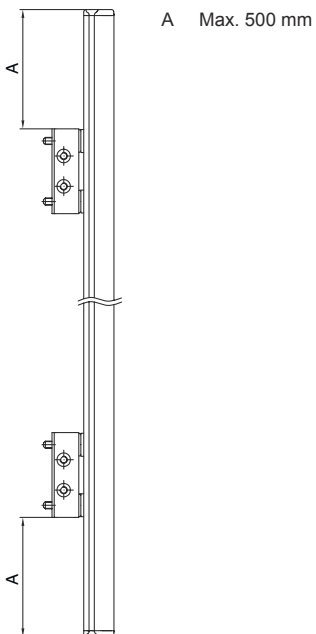

Dimensioned drawings




Mounting with BT-UM60 standard bracket

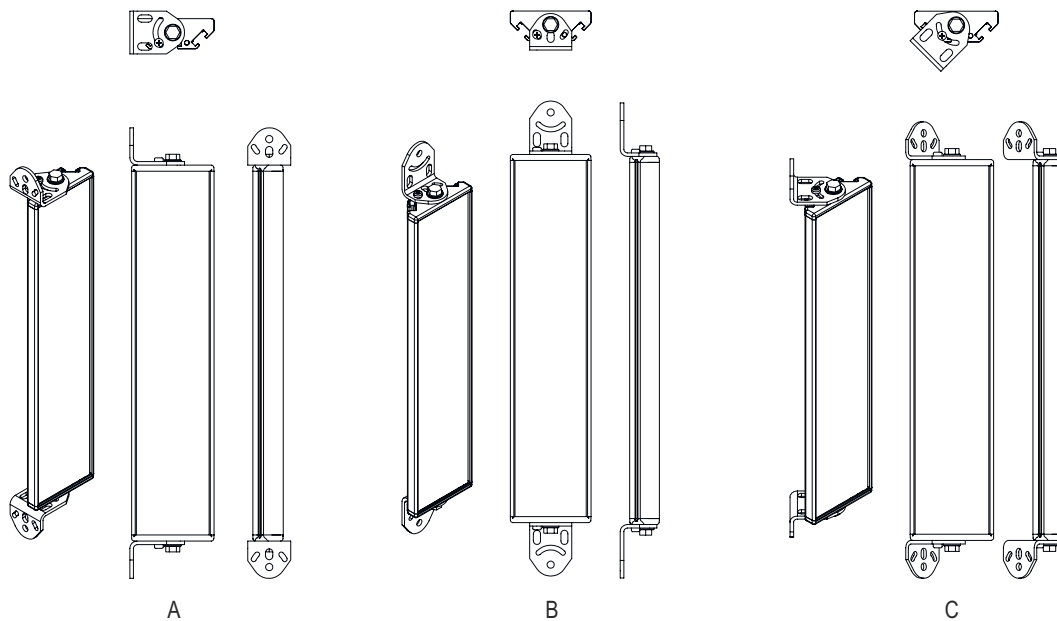


- A Lateral
- B Rear side
- C Adjustable at an angle (0 - 90°)

Dimensioned drawings

  Mounting with BT-SSD swiveling mounting bracket

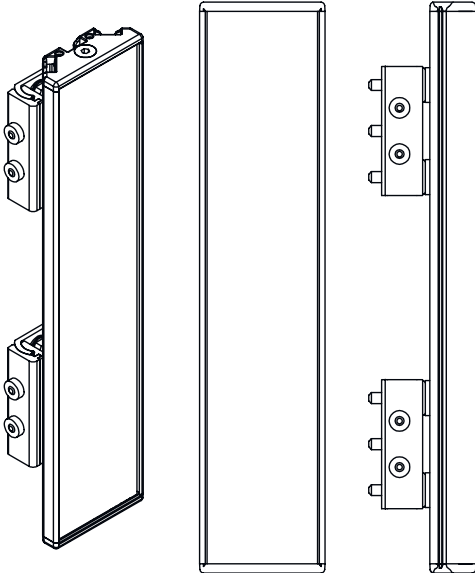

A

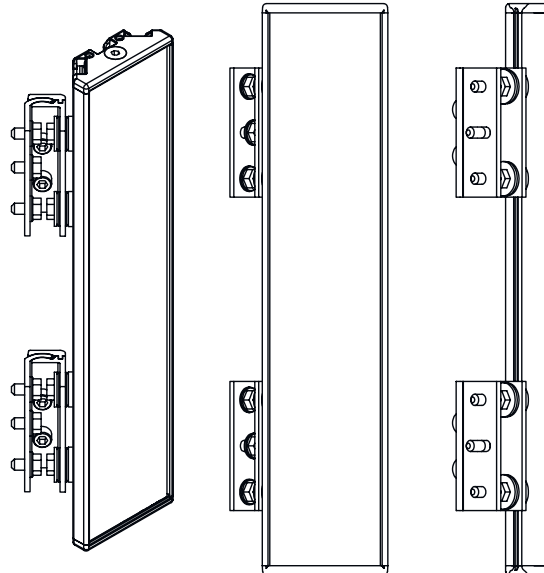

B

- A Rear side
- B Lateral 45°