


Technical data sheet Interconnection cable

Part no.: 50138360

KSS HS-USB-4A-RJ41-AA-T1-020

Contents

- Technical data
- Electrical connection

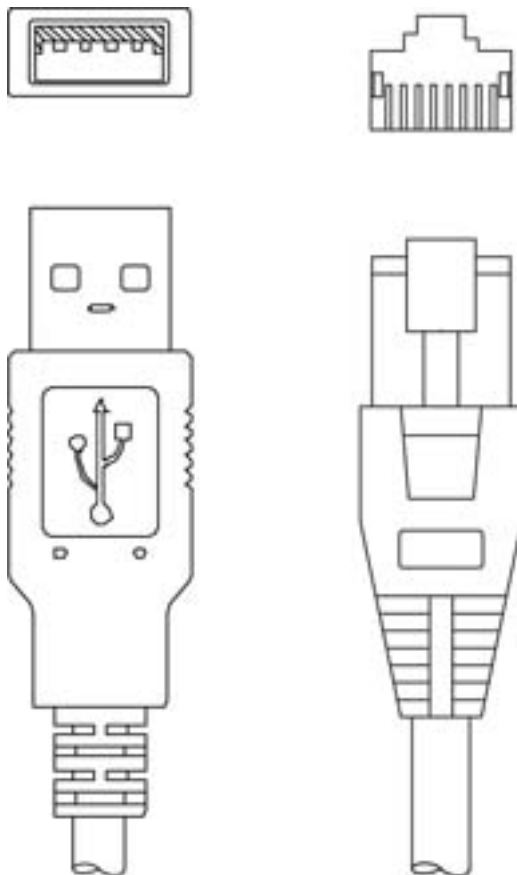

For illustration purposes only

Technical data

Basic data

Suitable for	HS 66x8
Suitable for interface	USB

Connection

Cable label	CBA-U46-S07ZAR
-------------	----------------

Connection 1

Type of connection	RJ41
Connector, LED	No

Connection 2

Type of connection	USB
Connector type	USB 2.0 Standard-A

Cable properties

Number of conductors	4 Piece(s)
Sheathing color	Black
Shielded	Yes
Cable diameter (external)	5.5 mm
Cable length	2,000 mm
Sheathing material	TPU
Suitability for drag chains	No

Classification

Customs tariff number	85444290
ECLASS 5.1.4	27279201
ECLASS 8.0	27279218
ECLASS 9.0	27060311
ECLASS 10.0	27060311
ECLASS 11.0	27060311
ECLASS 12.0	27060311
ECLASS 13.0	27060311
ECLASS 14.0	27060311
ECLASS 15.0	27060311
ECLASS 16.0	27060311
ETIM 5.0	EC001855
ETIM 6.0	EC001855
ETIM 7.0	EC001855
ETIM 8.0	EC001855
ETIM 9.0	EC001855
ETIM 10.0	EC001855
UNSPSC 26.08	26121604

Mechanical data

Net weight	90 g
------------	------


Electrical connection

Connection 1

Type of connection	RJ41
Connector, LED	No

Pin Pin assignment

1	Cable ID
2	+5 V DC
3	GND
4	n.c.
5	D+
6	n.c.
7	D-
8	n.c.
9	n.c.
10	+12 V DC

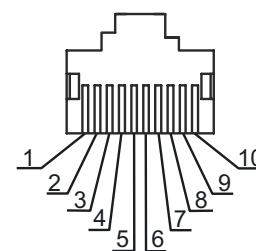

Connection 2

Type of connection	USB
Connector type	USB 2.0 Standard-A

Pin Pin assignment

1	+5 V DC
2	DATA-
3	DATA+
4	GND

