

Technical data sheet Interconnection cable

Part no.: 50115050

K-DS M12A-MA-8P-3m-S-PUR

Contents

- Technical data
- Electrical connection

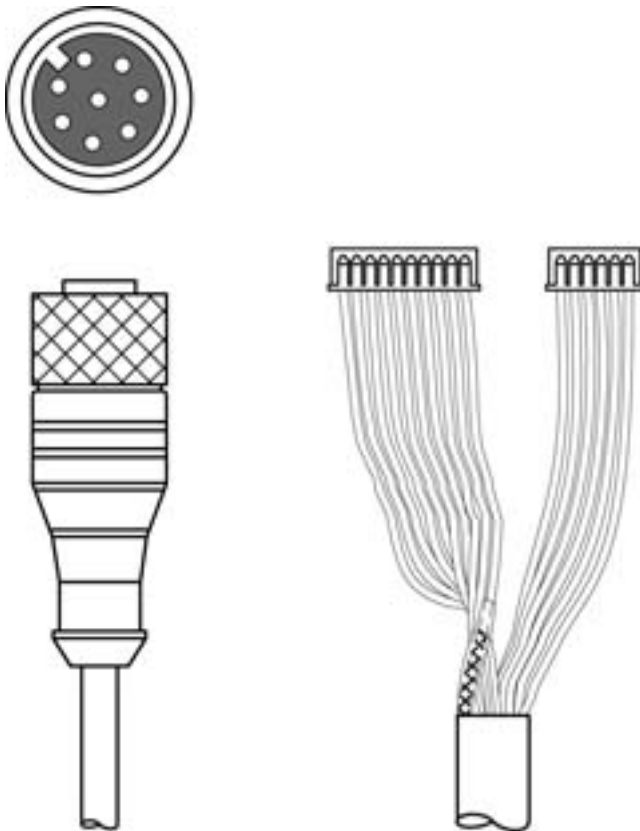


Figure can vary



Technical data

Electrical data

Performance data

Operating voltage	30 V AC/DC
-------------------	------------

Connection

Connection 1

Type of connection	Connector
Thread size	M12
Type	Female
No. of pins	8 -pin
Encoding	A-coded
Version	Axial
Connector, LED	No

Connection 2

Type of connection	JST ZHR
No. of pins	10 -pin
	6 -pin

Cable properties

Number of conductors	8 Piece(s)
Sheathing color	Gray
Shielded	Yes
Cable design	Interconnection cable
Cable length	3,000 mm
Sheathing material	PUR
Suitability for drag chains	No

Classification

Customs tariff number	85444290
ECLASS 5.1.4	27279201
ECLASS 8.0	27279218
ECLASS 9.0	27060311
ECLASS 10.0	27060311
ECLASS 11.0	27060311
ECLASS 12.0	27060311
ECLASS 13.0	27060311
ETIM 5.0	EC001855
ETIM 6.0	EC001855
ETIM 7.0	EC001855
ETIM 8.0	EC001855

Electrical connection

Connection 1

Type of connection	Connector
Thread size	M12
Type	Female
No. of pins	8 -pin
Encoding	A-coded
Version	Axial
Connector, LED	No

Connection 2

Type of connection	JST ZHR
No. of pins	10 -pin
	6 -pin