

Technical data sheet

Deflecting mirror

Part no.: 529602

UM60-225

Contents

- Technical data
- Dimensioned drawings



Figure can vary

Technical data

Basic data

Series	UM
Type, columns and mirrors	Deflecting mirror

Mechanical data

Dimension (W x H x L)	25 mm x 68 mm x 295 mm
Net weight	700 g
Housing color	Yellow, RAL 1021
Type of fastening	Groove mounting Swivel mount
Suitable for sensor	MLC 500, MLC 300 safety light curtains
Protected field height up to	225 mm
Mirror length	285 mm


Classification

Customs tariff number	70099200
ECLASS 5.1.4	27279207
ECLASS 8.0	27279207
ECLASS 9.0	27273605
ECLASS 10.0	27273605
ECLASS 11.0	27273605
ECLASS 12.0	27273605
ECLASS 13.0	27273605
ETIM 5.0	EC002467
ETIM 6.0	EC002467
ETIM 7.0	EC002467
ETIM 8.0	EC002467


Dimensioned drawings

All dimensions in millimeters

Mirror

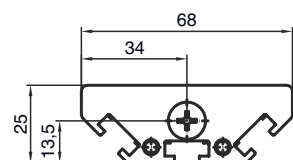


L Length = 295 mm
SL Mirror length = 285 mm

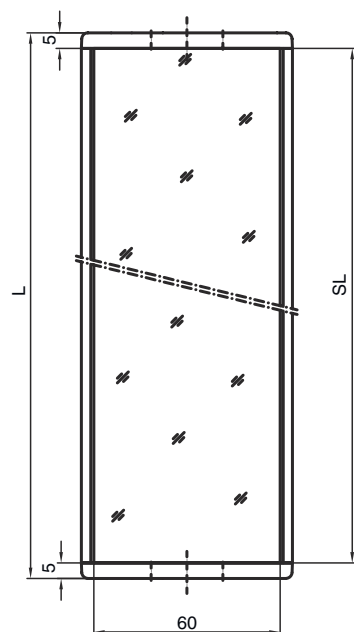


Dimensioned drawings

Mounting distances

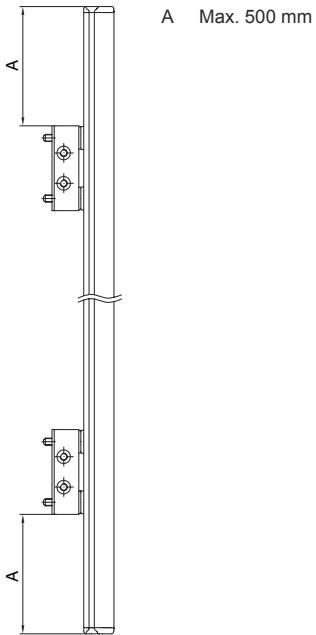




Mounting with BT-UM60 standard bracket

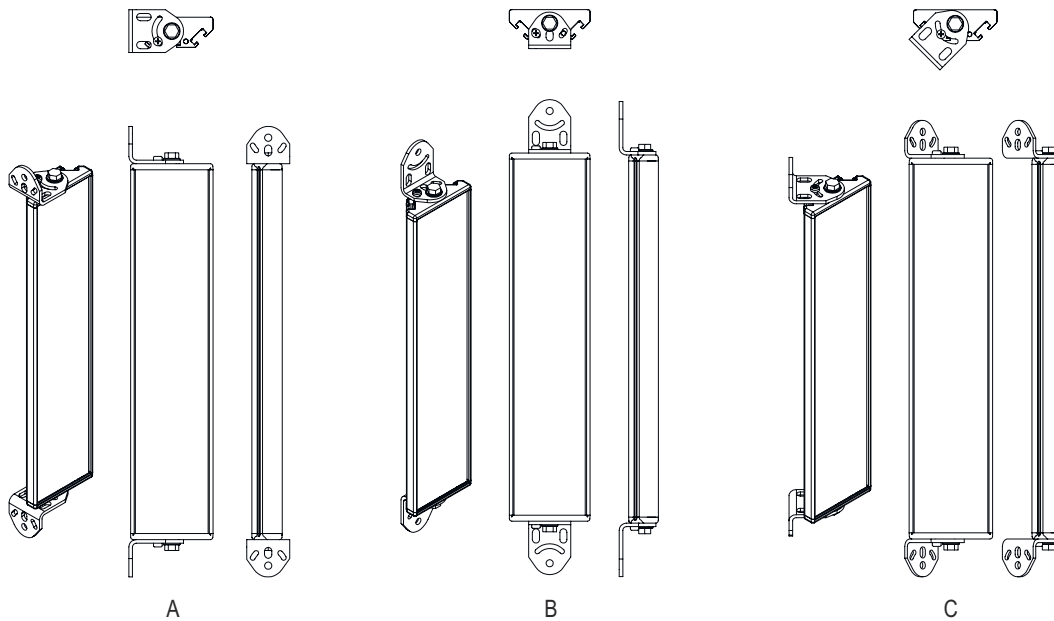


- A Lateral
- B Rear side
- C Adjustable at an angle (0 - 90°)

Dimensioned drawings

  Mounting with BT-SSD swiveling mounting bracket

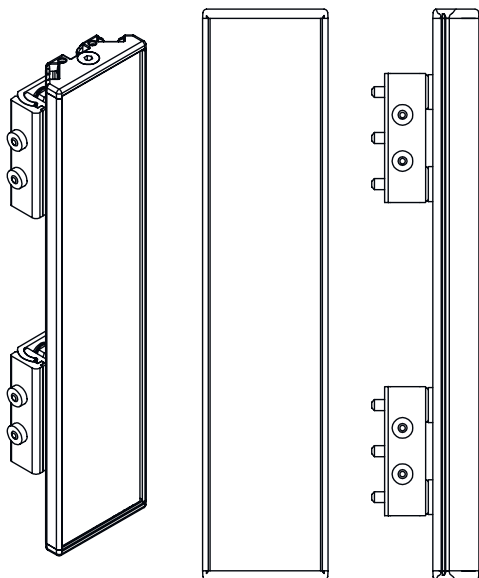

A

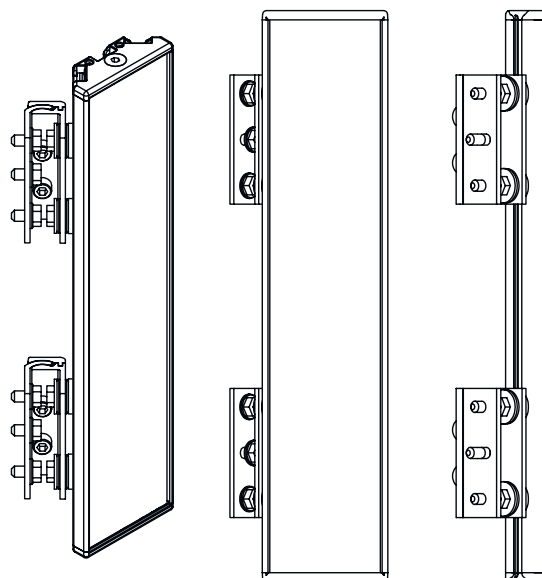

B

- A Rear side
- B Lateral 45°