

Technical data sheet


Connection cable

Part no.: 50011946

BK7 KB-092-12000- 4

Contents

- Technical data
- Electrical connection
- Circuit diagrams

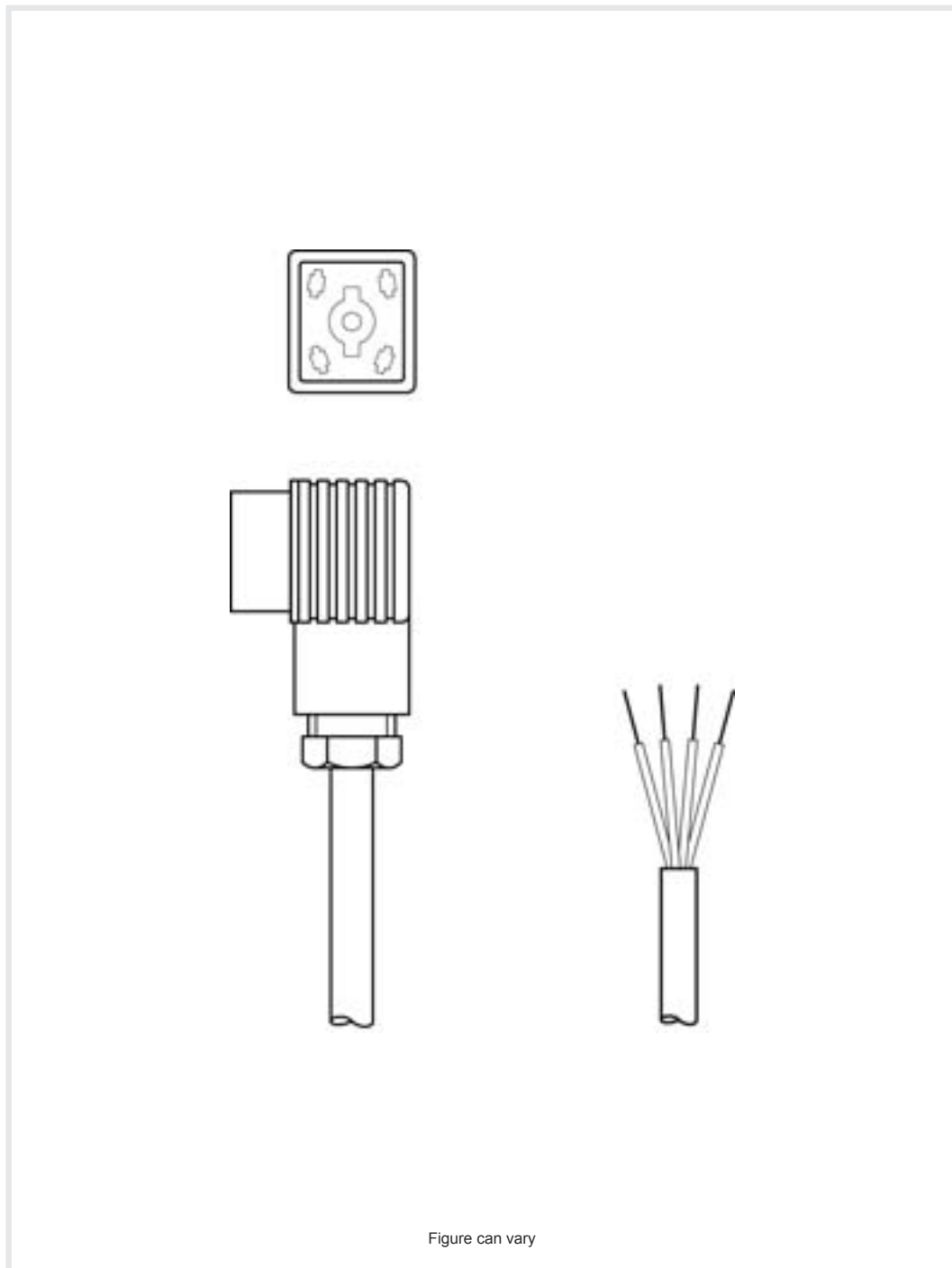

Technical data

Electrical data

Performance data

Supply voltage U_B	24 V, DC
Operating voltage	30 V AC/DC

Connection

Connection 1

Type of connection	Standard plug
Connector, LED	No
No. of pins	4 -pin
Version	Angled
Type	Female

Connection 2

Type of connection	Open end
--------------------	----------

Cable properties

Number of conductors	4 Piece(s)
Sheathing color	Black
Shielded	No
Cable design	Connection cable (open on one end)
Cable diameter (external)	4.7 mm
Cable length	12,000 mm
Sheathing material	PVC
Suitability for drag chains	No

Environmental data

Ambient temperature, operation	5 ... 40 °C
Ambient temperature, storage	-25 ... 70 °C

Classification

Customs tariff number	85444290
ECLASS 5.1.4	27279201
ECLASS 8.0	27279218
ECLASS 9.0	27060311
ECLASS 10.0	27060311
ECLASS 11.0	27060311
ECLASS 12.0	27060311
ECLASS 13.0	27060311
ETIM 5.0	EC001855
ETIM 6.0	EC001855
ETIM 7.0	EC001855
ETIM 8.0	EC001855

Electrical connection

Connection 1

Type of connection	Standard plug
Connector, LED	No
No. of pins	4 -pin
Version	Angled
Type	Female

Connection 2

Type of connection	Open end
--------------------	----------

Circuit diagrams

