

Technical data sheet

Adapter cable

Part no.: 549953

CB-MSI/D9-3000

Contents

- Technical data
- Electrical connection

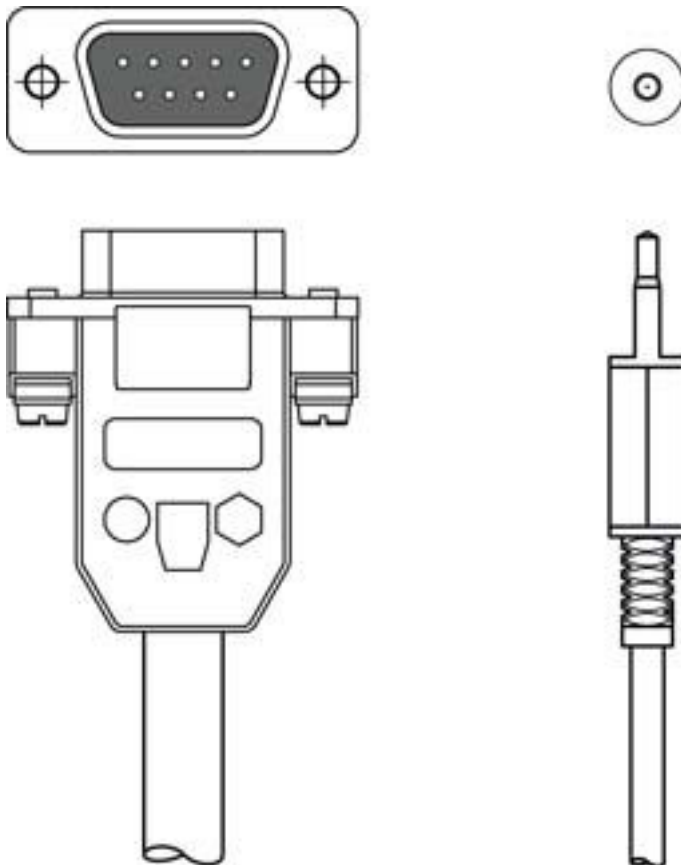


Figure can vary

Technical data

Connection

Connection 1

Type of connection	Sub-D
Connector, LED	No
Type	Female
No. of pins	9 -pin
Version	Axial

Connection 2

Type of connection	Jack plug
Version	Axial
Diameter	2.5 mm

Cable properties

Number of conductors	2 Piece(s)
Wire cross section	0.14 mm ²
Sheathing color	Black
Shielded	Yes
Cable design	Interconnection cable
Cable diameter (external)	4 mm
Cable length	3,000 mm
Sheathing material	PUR
Suitability for drag chains	No

Classification

Customs tariff number	85444290
ECLASS 5.1.4	27279201
ECLASS 8.0	27279218
ECLASS 9.0	27060311
ECLASS 10.0	27060313
ECLASS 11.0	27060313
ECLASS 12.0	27060313
ECLASS 13.0	27060313
ETIM 5.0	EC001855
ETIM 6.0	EC001855
ETIM 7.0	EC001855
ETIM 8.0	EC001855

Electrical connection

Connection 1

Type of connection	Sub-D
Connector, LED	No
Type	Female
No. of pins	9 -pin
Version	Axial

Connection 2

Type of connection	Jack plug
Version	Axial
Diameter	2.5 mm
No. of pins	2 -pin