

Technical data sheet Interconnection cable

Part no.: 50113396

KB DSub-9P-3000

Contents

- Technical data
- Electrical connection

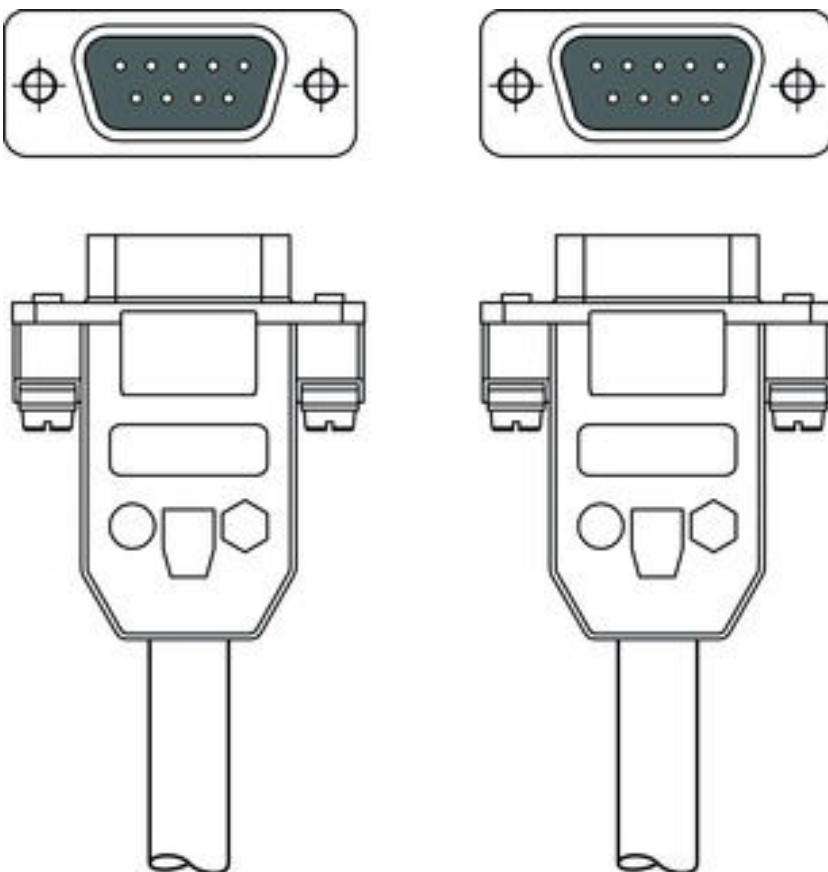


Figure can vary



Technical data

Basic data

Suitable for interface	RS 232
------------------------	--------

Connection

Connection 1

Function	Data interface
Type of connection	Sub-D
Connector, LED	No
Type	Female
No. of pins	9 -pin
Version	Axial

Connection 2

Function	Data interface
Type of connection	Sub-D
Type	Female
No. of pins	9 -pin
Version	Axial

Cable properties

Number of conductors	8 Piece(s)
Sheathing color	Gray
Shielded	Yes
Cable design	Interconnection cable
Cable diameter (external)	6 mm
Cable length	3,000 mm
Sheathing material	PVC
Suitability for drag chains	No

Classification

Customs tariff number	85444290
ECLASS 5.1.4	27279201
ECLASS 8.0	27279218
ECLASS 9.0	27060311
ECLASS 10.0	27060311
ECLASS 11.0	27060311
ECLASS 12.0	27060311
ECLASS 13.0	27060311
ETIM 5.0	EC001855
ETIM 6.0	EC001855
ETIM 7.0	EC001855
ETIM 8.0	EC001855


Electrical connection

Connection 1

Function	Data interface
Type of connection	Sub-D
Connector, LED	No
Type	Female
No. of pins	9 -pin
Version	Axial

Pin Pin assignment

1	DCD
2	RxD
3	TxD
4	DTR
5	GND
6	n.c.
7	RTS
8	CTS
9	RI

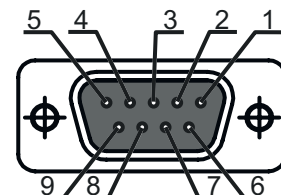

Connection 2

Function	Data interface
Type of connection	Sub-D
Type	Female
No. of pins	9 -pin
Version	Axial

Electrical connection

Pin	Pin assignment
1	DTR
2	TXD
3	RxD
4	DCD
5	GND
6	n.c.
7	CTS
8	RTS
9	RI

