

## Technical data sheet

### Adapter cable

Part no.: 50134949

KDS ET-RJ45-A-USB3-A-P4-000

#### Contents

- Technical data
- Electrical connection

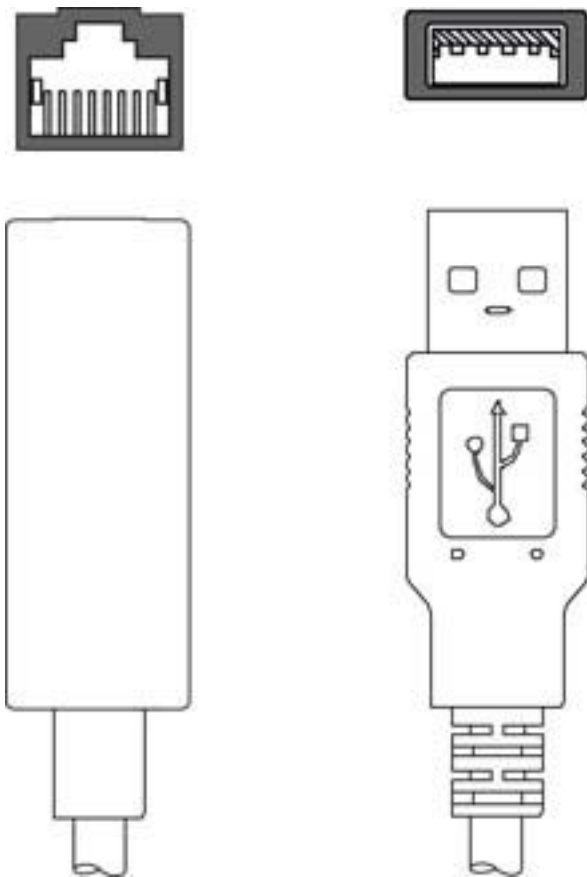


Figure can vary

## Technical data

### Basic data

Suitable for interface	Ethernet
------------------------	----------

### Interface

#### Ethernet

Transmission speed	10/100/1000Mbps RJ45 Ethernet port
--------------------	------------------------------------

### Connection

Number of connections	2 Piece(s)
-----------------------	------------

#### Connection 1

Type of connection	RJ45
Version	Axial

#### Connection 2

Type of connection	USB
Connector type	USB 3.0 Standard-A

### Mechanical data

Design	Cubic
Dimension (W x H x L)	71 mm x 26 mm x 16.2 mm
Housing color	White

### Environmental data

Ambient temperature, operation	0 ... 40 °C
Ambient temperature, storage	-40 ... 70 °C

### Certifications

Degree of protection	IP 20
Certifications	FCC
	RoHS

### Software

System requirements	Windows XP/Vista/7/8/8.1, Mac OS X 10.5/10.6/10.7/10.8/10.9/10.10/, Linux-based system
---------------------	--

### Classification

Customs tariff number	85176200
ECLASS 5.1.4	27069190
ECLASS 8.0	27069190
ECLASS 9.0	27069190
ECLASS 10.0	27060313
ECLASS 11.0	27060313
ECLASS 12.0	27060313
ECLASS 13.0	27060313
ETIM 5.0	EC001855
ETIM 6.0	EC001855
ETIM 7.0	EC001855
ETIM 8.0	EC001855

## Electrical connection

### Connection 1

Type of connection	RJ45
--------------------	------

### Connection 2

Type of connection	USB
Connector type	USB 3.0 Standard-A