

## Technical data sheet Interconnection cable

Part no.: 150769

CB-M12-CC30

### Contents

- Technical data
- Electrical connection
- Circuit diagrams

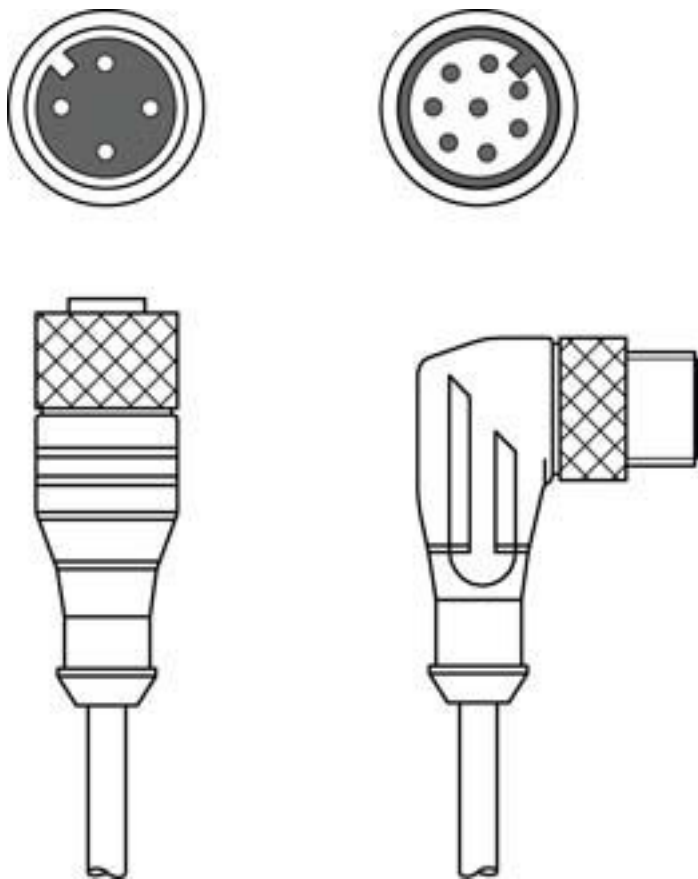


Figure can vary



## Technical data

### Connection

#### Connection 1

Type of connection	Connector
Thread size	M12
Type	Female
No. of pins	4 -pin
Encoding	A-coded
Version	Axial
Lock	Screw fitting

#### Connection 2

Type of connection	Connector
Thread size	M12
Type	Male
No. of pins	8 -pin
Encoding	A-coded
Version	Angled

### Cable properties

Shielded	No
Cable design	Interconnection cable
Cable length	3,000 mm
Suitability for drag chains	No

### Classification

Customs tariff number	85444290
eCl@ss 5.1.4	27279201
eCl@ss 8.0	27279218
eCl@ss 9.0	27060311
eCl@ss 10.0	27060311
eCl@ss 11.0	27060311
ETIM 5.0	EC001855
ETIM 6.0	EC001855
ETIM 7.0	EC001855

## Electrical connection

### Connection 1

Type of connection	Connector
Thread size	M12
Type	Female
No. of pins	4 -pin
Encoding	A-coded
Version	Axial
Lock	Screw fitting

### Connection 2

Type of connection	Connector
Thread size	M12
Type	Male
No. of pins	8 -pin
Encoding	A-coded
Version	Angled

## Circuit diagrams

### Wiring schematic

