

Technical data sheet


Connection cable

Part no.: 50106977

KB-014S- 10000-14

Contents

- Technical data
- Electrical connection

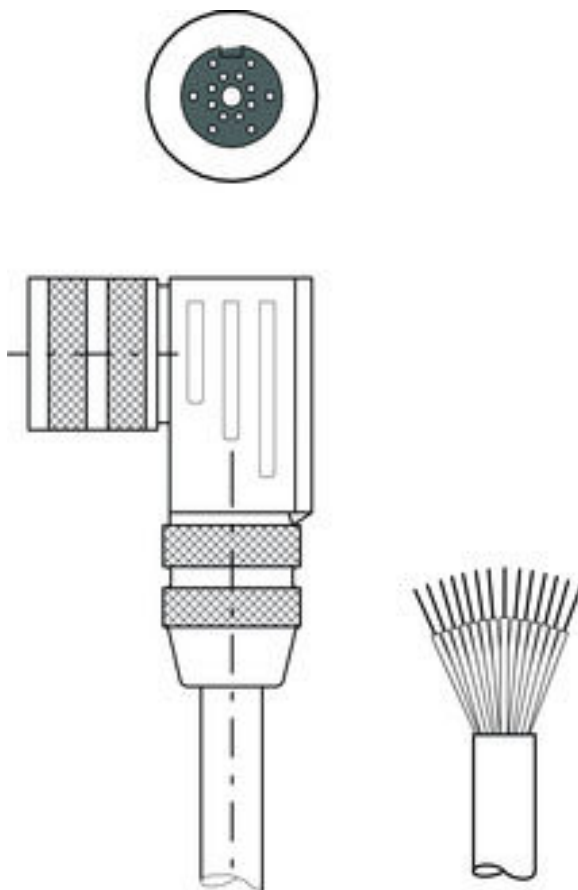

For illustration purposes only



Technical data

Basic data

Application	Chemical resistant
-------------	--------------------

Electrical data

Performance data

Operating voltage	30 V AC/DC
-------------------	------------

Connection

Connection 1

Type of connection	Connector
Thread size	M16
Type	Female
No. of pins	14 -pin
Encoding	A-coded
Version	Angled
Connector, LED	No

Connection 2

Type of connection	Open end
--------------------	----------

Cable properties

Number of conductors	14 Piece(s)
Shielded	Yes
Cable design	Connection cable (open on one end)
Cable diameter (external)	6.7 mm
Cable length	10,000 mm
Sheathing material	PVC
Suitability for drag chains	No

Classification

Customs tariff number	85444290
ECLASS 5.1.4	27279201
ECLASS 8.0	27279218
ECLASS 9.0	27060311
ECLASS 10.0	27060311
ECLASS 11.0	27060311
ECLASS 12.0	27060311
ECLASS 13.0	27060311
ECLASS 14.0	27060311
ECLASS 15.0	27060311
ETIM 5.0	EC001855
ETIM 6.0	EC001855
ETIM 7.0	EC001855
ETIM 8.0	EC001855
ETIM 9.0	EC001855
ETIM 10.0	EC001855

Electrical connection

Connection 1

Type of connection	Connector
Thread size	M16
Type	Female
No. of pins	14 -pin
Encoding	A-coded
Version	Angled
Connector, LED	No

Connection 2

Type of connection	Open end
--------------------	----------