


Technical data sheet Interconnection cable

Part no.: 50104025

KB 031-2000-01

Contents

- Technical data
- Electrical connection

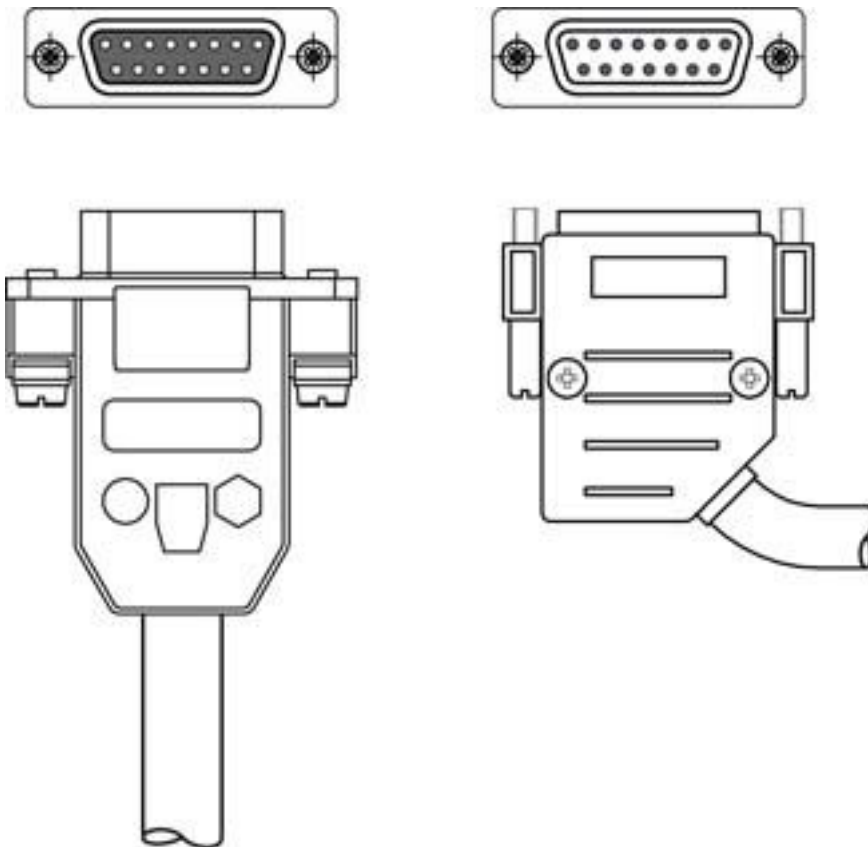

For illustration purposes only



Technical data

Basic data

Electrical data

Performance data

Operating voltage30 V AC/DC

Connection

Connection 1

Type of connectionSub-D

Connector, LEDNo

TypeFemale

No. of pins15 -pin

VersionAxial

Connection 2

Type of connectionSub-D

Cable properties

Number of conductors15 Piece(s)

ShieldedYes

Cable designConnection cable (open on one end)

Cable diameter (external)8.1 mm

Cable length2,000 mm

Suitability for drag chainsNo

Classification

Customs tariff number85444290

ECLASS 5.1.427279201

ECLASS 8.027279218

ECLASS 9.027060311

ECLASS 10.027060311

ECLASS 11.027060311

ECLASS 12.027060311

ECLASS 13.027060311

ECLASS 14.027060311

ETIM 5.0EC001855

ETIM 6.0EC001855

ETIM 7.0EC001855

ETIM 8.0EC001855

ETIM 9.0EC001855

Electrical connection

Connection 1

Type of connectionSub-D

Connector, LEDNo

TypeFemale

No. of pins15 -pin

VersionAxial

Connection 2

Type of connectionSub-D

TypeMale

No. of pins15 -pin

VersionAngled