


Technical data sheet Interconnection cable

Part no.: 50148540

KDS S-12-CA-M12-5A-P1-004-78X

Contents

- Technical data
- Electrical connection
- Circuit diagrams

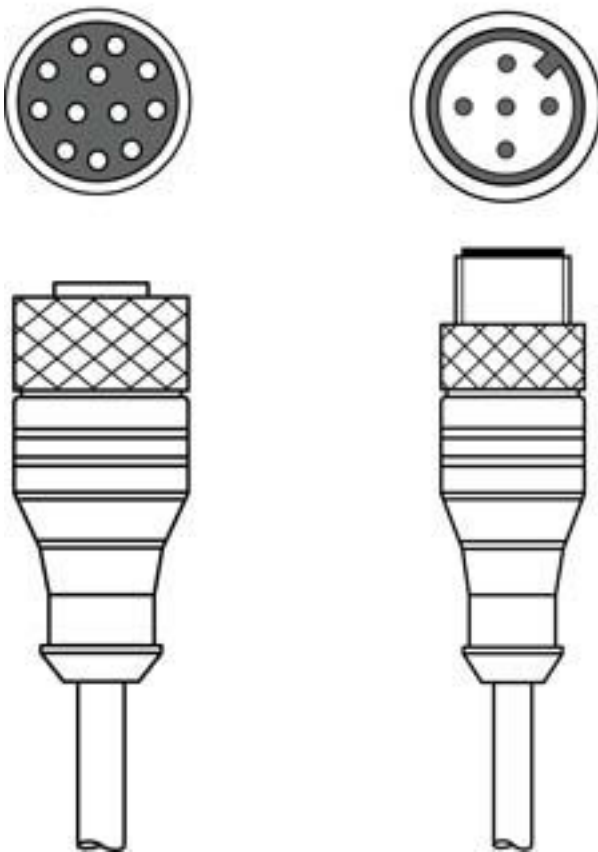

For illustration purposes only

Technical data

Basic data

Suitable for	DCR 1048i
	IVS 1048i

Connection

Connection 1

Type of connection	Connector
Thread size	M12
Type	Female
No. of pins	12 -pin
Encoding	A-coded
Version	Axial

Connection 2

Type of connection	Connector
Thread size	M12
Type	Male
No. of pins	5 -pin
Encoding	A-coded
Version	Axial

Cable properties

Number of conductors	4 Piece(s)
Sheathing color	Black
Shielded	Yes
Cable design	Interconnection cable
Cable length	200 mm
Sheathing material	PUR
Suitability for drag chains	No

Classification

Customs tariff number	85444290
ECLASS 5.1.4	27279201
ECLASS 8.0	27279218
ECLASS 9.0	27060311
ECLASS 10.0	27060311
ECLASS 11.0	27060311
ECLASS 12.0	27060311
ECLASS 13.0	27060311
ECLASS 14.0	27060311
ETIM 5.0	EC001855
ETIM 6.0	EC001855
ETIM 7.0	EC001855
ETIM 8.0	EC001855
ETIM 9.0	EC001855

Electrical connection

Connection 1

Type of connection	Connector
Thread size	M12
Type	Female
No. of pins	12 -pin
Encoding	A-coded
Version	Axial

Connection 2

Type of connection	Connector
Thread size	M12
Type	Male
No. of pins	5 -pin
Encoding	A-coded
Version	Axial

Circuit diagrams

Wiring schematic

