


Technical data sheet Interconnection cable

Part no.: 50120436

KB RS232-1 HS 65x8

Contents

- Technical data
- Electrical connection

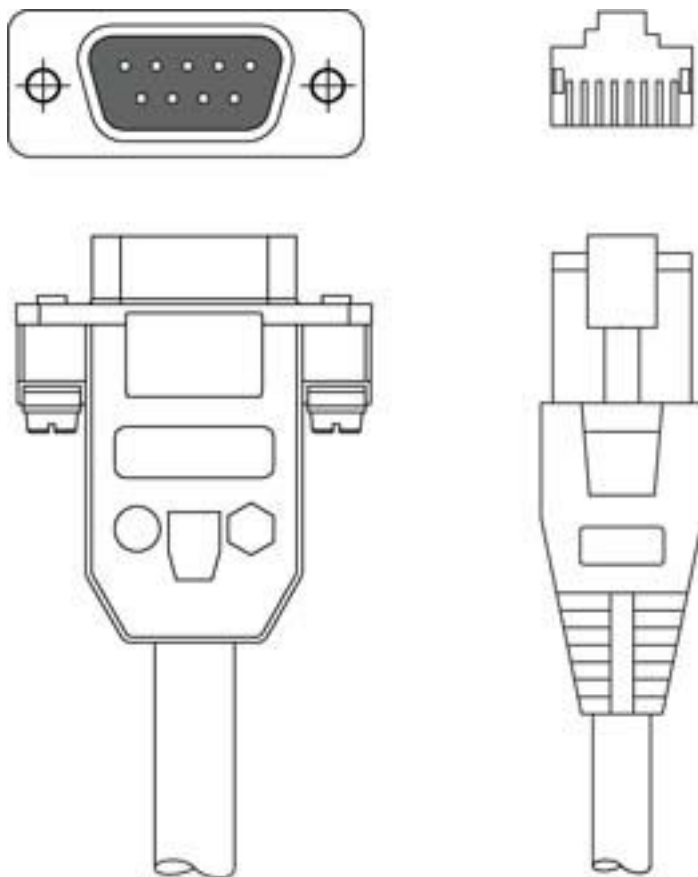

For illustration purposes only



Technical data

Basic data

Suitable for	HS 65x8
Suitable for interface	RS 232

Connection

Connection 1

Type of connection	RJ41
Connector, LED	No

Connection 2

Type of connection	Sub-D
Type	Female
No. of pins	9 -pin
Version	Axial

Cable properties

Number of conductors	6 Piece(s)
Sheathing color	Gray
Shielded	Yes
Cable design	Helix cable
Cable diameter (external)	5 mm
Cable length	2,800 mm
Sheathing material	TPE
Suitability for drag chains	No

Mechanical data

Net weight	107 g
------------	-------

Operation and display

Classification

Customs tariff number	85444290
ECLASS 5.1.4	27279201
ECLASS 8.0	27279218
ECLASS 9.0	27060311
ECLASS 10.0	27060311
ECLASS 11.0	27060311
ECLASS 12.0	27060311
ECLASS 13.0	27060311
ECLASS 14.0	27060311
ECLASS 15.0	27060311
ECLASS 16.0	27060311
ETIM 5.0	EC001855
ETIM 6.0	EC001855
ETIM 7.0	EC001855
ETIM 8.0	EC001855
ETIM 9.0	EC001855
ETIM 10.0	EC001855
UNSPSC 26.08	26121604


Electrical connection

Connection 1

Type of connection	RJ41
Connector, LED	No

Pin Pin assignment

1	Shield
2	n.c.
3	GND
4	TxD
5	RxD
6	CTS
7	+5 V DC
8	RTS
9	n.c.
10	n.c.

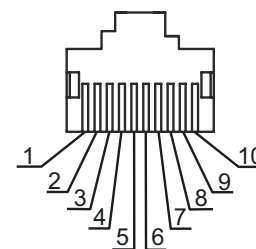

Connection 2

Type of connection	Sub-D
Type	Female
No. of pins	9 -pin
Version	Axial

Electrical connection

Pin	Pin assignment
1	n.c.
2	TxD
3	RxD
4	n.c.
5	GND
6	DTR
7	CTS
8	RTS
9	V+

