

Technical data sheet

Cover hood

Part no.: 50148550

AC IVS 1048-POL

Contents

- Technical data
- Dimensioned drawings



For illustration purposes only

Technical data

Basic data

Type	Cover hood with crossed polarization filters
Suitable for	DCR 1048i IVS 1048i

Optical data

Transmission	40%
Note	The cover hood cannot be used with the lens Lens-S-M12-4F4 and Lens-S-M12-4F8. The degree of protection of the sensor without cover hood is IP40.

Mechanical data


Design	Ring
Thickness	17 mm
Outer diameter	45 mm
Material	PMMA (lens cover) PVAL (optical film)

Classification

Customs tariff number	90022000
ECLASS 5.1.4	27310203
ECLASS 8.0	27310203
ECLASS 9.0	27310203
ECLASS 10.0	27273603
ECLASS 11.0	27273603
ECLASS 12.0	27273603
ECLASS 13.0	27273603
ECLASS 14.0	27273603
ETIM 5.0	EC002498
ETIM 6.0	EC003015
ETIM 7.0	EC003015
ETIM 8.0	EC003015
ETIM 9.0	EC003015

Dimensioned drawings

All dimensions in millimeters

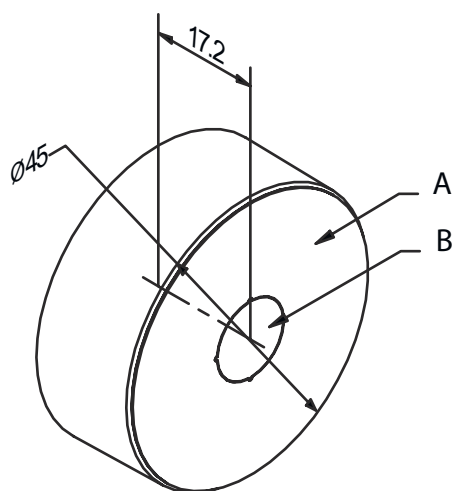

- A Polarization filter
- B Polarization filter rotated through 90°