

Technical data sheet

Adapter

Part no.: 50134904

KDS U-M8-4A-M8-3A-P1-000

Contents

- Technical data
- Electrical connection
- Circuit diagrams
- Accessories



For illustration purposes only



Technical data

Electrical data

Performance data

Operating voltage	Max. 50 V AC / 60 V DC
-------------------	------------------------

Connection

Connection 1

Type of connection	Connector
Thread size	M8
Type	Female
No. of pins	4 -pin
Version	Axial

Connection 2

Type of connection	Connector
Thread size	M8
Type	Male
No. of pins	3 -pin
Version	Axial

Cable properties

Shielded	No
----------	----

Mechanical data

Width across flats	9 mm
Net weight	9 g
Material	PUR

Certifications

Degree of protection	IP 67
----------------------	-------

Classification

Customs tariff number	85366990
ECLASS 5.1.4	27279201
ECLASS 8.0	27440104
ECLASS 9.0	27069190
ECLASS 10.0	27440106
ECLASS 11.0	27440106
ECLASS 12.0	27440106
ECLASS 13.0	27440106
ECLASS 14.0	27440106
ECLASS 15.0	27440106
ECLASS 16.0	27440106
ETIM 5.0	EC002498
ETIM 6.0	EC002498
ETIM 7.0	EC002925
ETIM 8.0	EC002925
ETIM 9.0	EC002925
ETIM 10.0	EC002925
UNSPSC 26.08	32151900

Electrical connection


Connection 1

Type of connection	Connector
Thread size	M8
Type	Female
No. of pins	4 -pin
Version	Axial

Connection 2


Type of connection	Connector
Thread size	M8
Type	Male
No. of pins	3 -pin
Version	Axial

Circuit diagrams

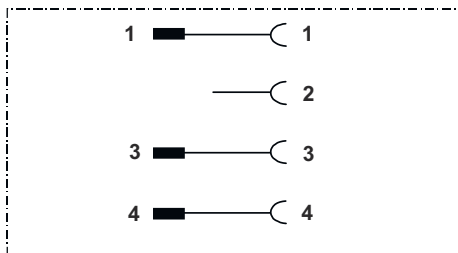


Accessories

General

	Part no.	Designation	Article	Description
	50132266	TT-Set 0,6-13	Tool	Type: Torque key Width across flats: 13 mm Torque: 0.6 N·m Material: Plastic, Stainless steel Ambient temperature: -40 ... 120 °C

Note

 A list with all available accessories can be found on the Leuze website in the Download tab of the article detailed page.