


## Technical data sheet Interconnection cable

Part no.: 50120432

KB USB-1 HS 65x8

### Contents

- Technical data
- Electrical connection

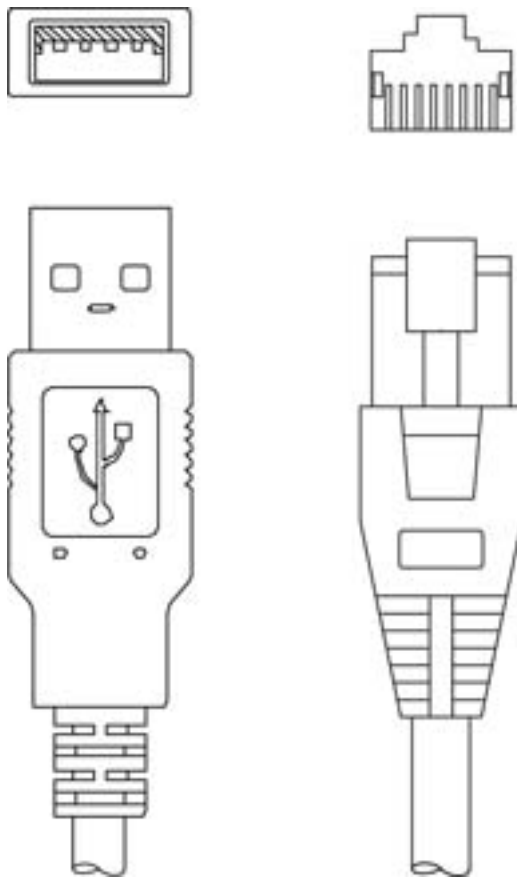

For illustration purposes only



## Technical data

### Basic data

Suitable for	HS 65x8
Suitable for interface	USB

### Connection

#### Connection 1

Type of connection	RJ41
Connector, LED	No

#### Connection 2

Type of connection	USB
Connector type	USB 1.1 Standard-A

#### Cable properties

Number of conductors	4 Piece(s)
Sheathing color	Gray
Shielded	Yes
Cable design	Helix cable
Cable diameter (external)	4 mm
Cable length	2,800 mm
Sheathing material	TPU
Suitability for drag chains	No

### Mechanical data

Net weight	95 g
------------	------

### Classification

Customs tariff number	85444290
ECLASS 5.1.4	27279201
ECLASS 8.0	27279218
ECLASS 9.0	27060311
ECLASS 10.0	27060311
ECLASS 11.0	27060311
ECLASS 12.0	27060311
ECLASS 13.0	27060311
ECLASS 14.0	27060311
ECLASS 15.0	27060311
ECLASS 16.0	27060311
ETIM 5.0	EC001855
ETIM 6.0	EC001855
ETIM 7.0	EC001855
ETIM 8.0	EC001855
ETIM 9.0	EC001855
ETIM 10.0	EC001855
UNSPSC 26.08	26121604


## Electrical connection

### Connection 1

Type of connection	RJ41
Connector, LED	No

#### Pin Pin assignment

1	Shield
2	n.c.
3	GND
4	n.c.
5	n.c.
6	n.c.
7	+5 V DC
8	n.c.
9	DATA+
10	DATA-

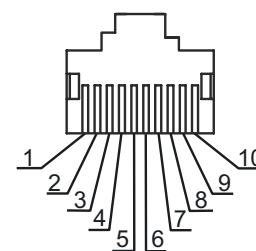

### Connection 2

Type of connection	USB
Connector type	USB 1.1 Standard-A

#### Pin Pin assignment

1	+5 V DC
2	DATA-
3	DATA-
4	GND

