

Technical data sheet


Distribution cable

Part no.: 150766

CB-M12-SC44

Contents

- Technical data
- Dimensioned drawings
- Electrical connection
- Circuit diagrams

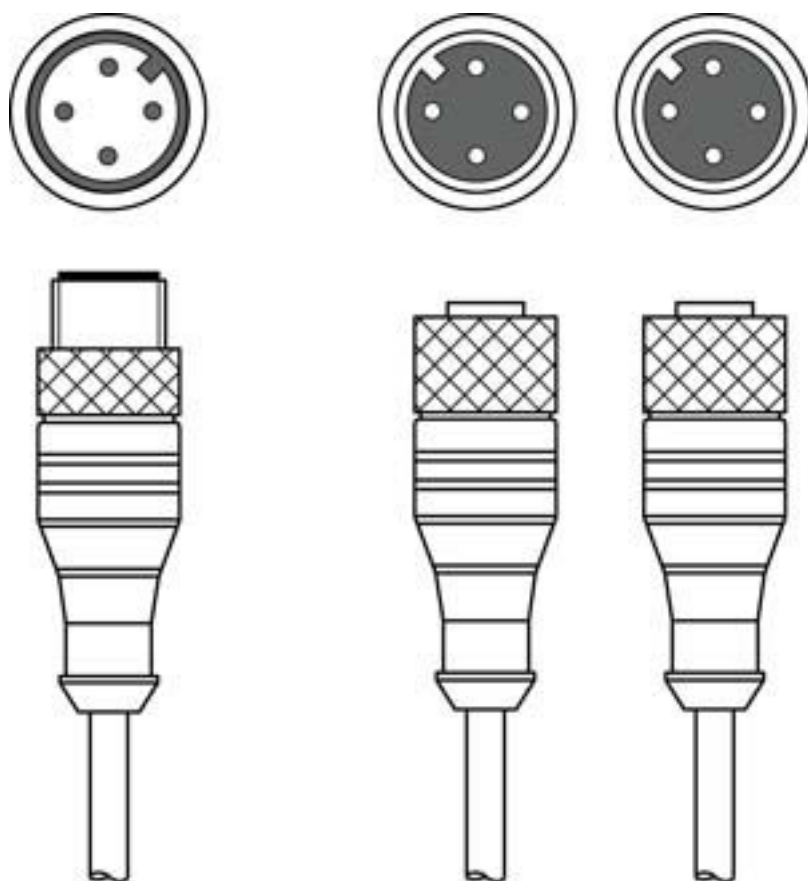

For illustration purposes only

Technical data

Basic data

Suitable for	COMPACTplus-m multiple light beam safety devices
	COMPACTplus-m safety light curtains
	COMPACTplus-ml multiple light beam safety devices

Connection

Connection 1

Type of connection	Connector
Thread size	M12
Type	Male
No. of pins	4 -pin
Encoding	A-coded
Version	Axial

Connection 2

Type of connection	Connector
Thread size	M12
Type	Female
No. of pins	4 -pin
Encoding	A-coded
Version	Axial

Connection 3

Type of connection	Connector
Thread size	M12
Type	Female
No. of pins	4 -pin
Encoding	A-coded
Version	Axial

Cable properties

Number of conductors	4 Piece(s)
Shielded	No
Cable design	Distribution cable
Cable length	1,000 mm
Suitability for drag chains	No

Mechanical data

Net weight	81 g
------------	------


Certifications

Classification

Customs tariff number	85444290
ECLASS 5.1.4	27279201
ECLASS 8.0	27279218
ECLASS 9.0	27060311
ECLASS 10.0	27060311
ECLASS 11.0	27060311
ECLASS 12.0	27060311
ECLASS 13.0	27060311
ECLASS 14.0	27060311
ECLASS 15.0	27060311
ECLASS 16.0	27060311
ETIM 5.0	EC001855
ETIM 6.0	EC001855
ETIM 7.0	EC001855
ETIM 8.0	EC001855
ETIM 9.0	EC001855
ETIM 10.0	EC001855
UNSPSC 26.08	26121604

Dimensioned drawings

All dimensions in millimeters

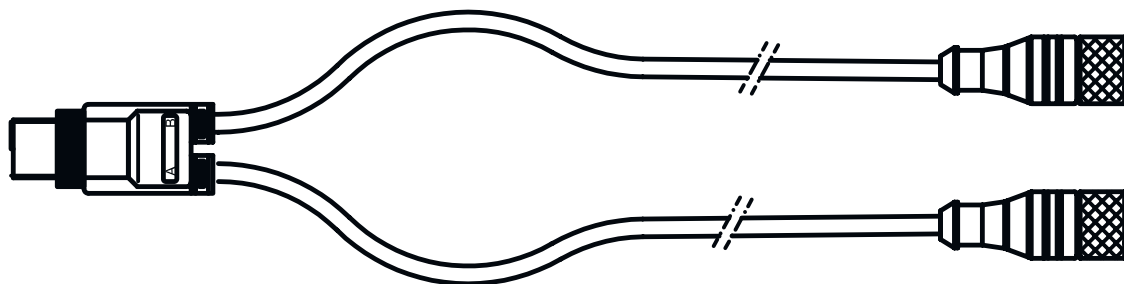

Electrical connection

Connection 1

Type of connection	Connector
Thread size	M12
Type	Male
No. of pins	4 -pin
Encoding	A-coded
Version	Axial

Connection 2

Type of connection	Connector
Thread size	M12
Type	Female
No. of pins	4 -pin
Encoding	A-coded
Version	Axial

Connection 3

Type of connection	Connector
Thread size	M12
Type	Female
No. of pins	4 -pin
Encoding	A-coded
Version	Axial

Circuit diagrams

