


## Technical data sheet Interconnection cable

Part no.: 50138358

KY-HS-DDS-D9AJ2ARAA-020-T1

### Contents

- Technical data
- Electrical connection

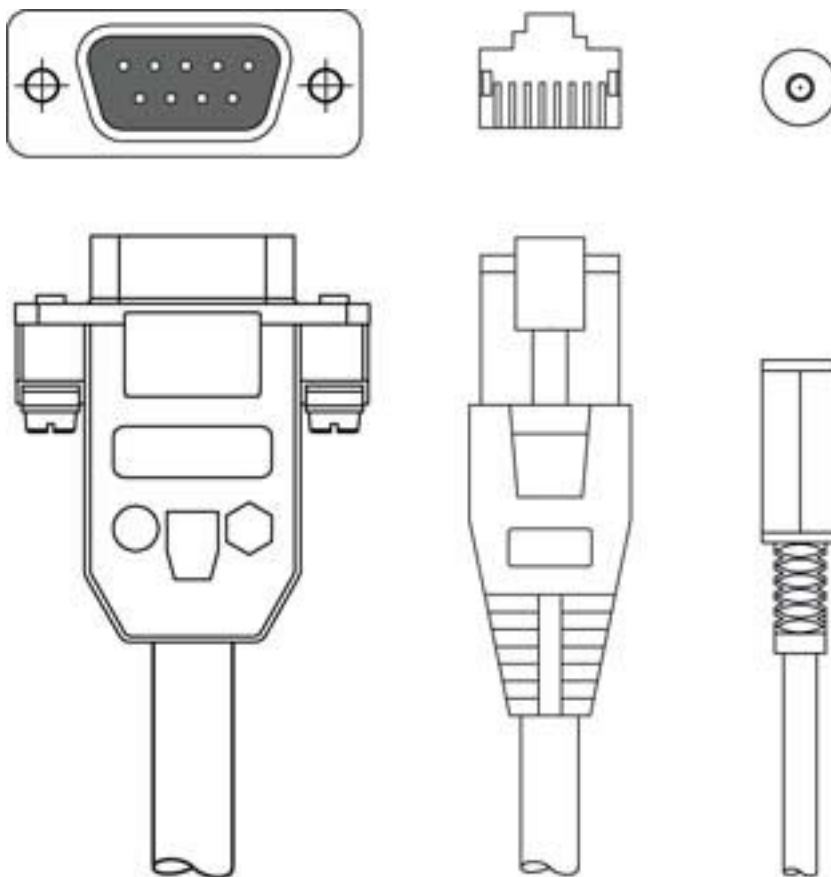

For illustration purposes only

## Technical data

### Basic data

Suitable for	HS 66x8
Suitable for interface	RS 232

### Connection

#### Connection 1

Type of connection	RJ41
--------------------	------

#### Connection 2

Type of connection	Sub-D
Type	Female
No. of pins	9 -pin
Version	Axial

#### Connection 3

Type of connection	Connector
Thread size	Pluggable
Type	Female
No. of pins	2 -pin
Version	Axial

#### Cable properties

Number of conductors	6 Piece(s)
Sheathing color	Black
Shielded	Yes
Cable diameter (external)	6 mm
Cable length	2,000 mm
Sheathing material	TPU
Suitability for drag chains	No

### Mechanical data

Net weight	126 g
------------	-------

### Classification

Customs tariff number	85444290
ECLASS 5.1.4	27279201
ECLASS 8.0	27279218
ECLASS 9.0	27060311
ECLASS 10.0	27060311
ECLASS 11.0	27060311
ECLASS 12.0	27060311
ECLASS 13.0	27060311
ECLASS 14.0	27060311
ECLASS 15.0	27060311
ECLASS 16.0	27060311
ETIM 5.0	EC001855
ETIM 6.0	EC001855
ETIM 7.0	EC001855
ETIM 8.0	EC001855
ETIM 9.0	EC001855
ETIM 10.0	EC001855
UNSPSC 26.08	26121604


## Electrical connection

### Connection 1

Type of connection	RJ41
--------------------	------

#### Pin Pin assignment

1	Cable ID
2	+5 V DC
3	GND
4	TxD RS 232
5	RxD RS232
6	RTS RS 232
7	CTS RS 232
8	n.c.
9	n.c.
10	+12 V DC

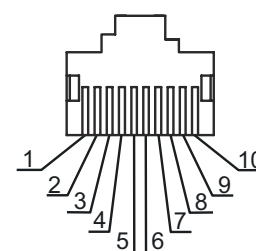


### Connection 2

Type of connection	Sub-D
Type	Female
No. of pins	9 -pin
Version	Axial

## Electrical connection

Pin	Pin assignment
1	Shield
2	TxD
3	RxD
4	n.c.
5	GND
6	n.c.
7	CTS
8	RTS
9	n.c.

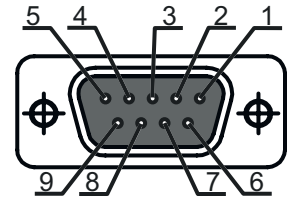

### Connection 3

Type of connection	Connector
Thread size	Pluggable
Type	Female
No. of pins	2 -pin
Version	Axial