

## Technical data sheet


### Adapter cable

Part no.: 50110677

KB-RS232-USB

#### Contents

- Technical data
- Electrical connection

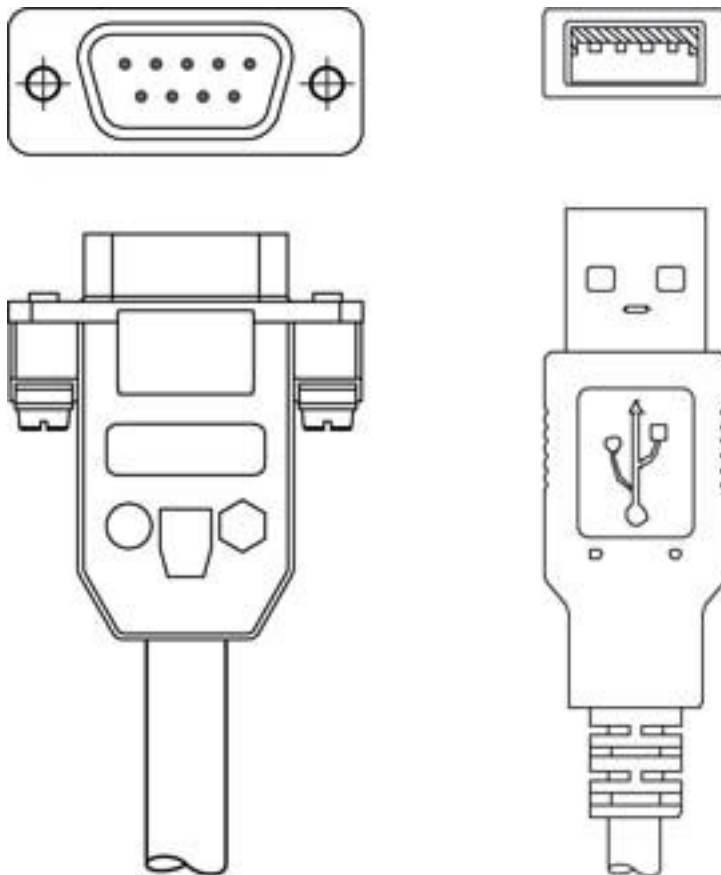

For illustration purposes only

## Technical data

### Basic data

Suitable for interface	RS 232
	USB

### Connection

#### Connection 1

Type of connection	Sub-D
Connector, LED	No
Type	Male
No. of pins	9 -pin
Version	Axial

#### Connection 2

Type of connection	USB
Connector type	USB 1.1 Standard-A

#### Cable properties

Number of conductors	4 Piece(s)
Sheathing color	Black
Shielded	Yes
Cable design	Interconnection cable
Cable diameter (external)	5 mm
Cable length	1,000 mm
Sheathing material	PVC
Suitability for drag chains	No

### Mechanical data

Net weight	68 g
------------	------

### Operation and display

#### Classification

Customs tariff number	85444290
ECLASS 5.1.4	27279201
ECLASS 8.0	27279218
ECLASS 9.0	27060311
ECLASS 10.0	27060313
ECLASS 11.0	27060313
ECLASS 12.0	27060313
ECLASS 13.0	27060313
ECLASS 14.0	27060313
ECLASS 15.0	27060313
ECLASS 16.0	27060313
ETIM 5.0	EC001855
ETIM 6.0	EC001855
ETIM 7.0	EC001855
ETIM 8.0	EC001855
ETIM 9.0	EC001855
ETIM 10.0	EC001855
UNSPSC 26.08	26121600

## Electrical connection

### Connection 1

Type of connection	Sub-D
Connector, LED	No
Type	Male
No. of pins	9 -pin
Version	Axial

### Connection 2

Type of connection	USB
Connector type	USB 1.1 Standard-A