

## Technical data sheet


### Connection cable

Part no.: 50011946

BK7 KB-092-12000- 4

#### Contents

- Technical data
- Electrical connection
- Circuit diagrams

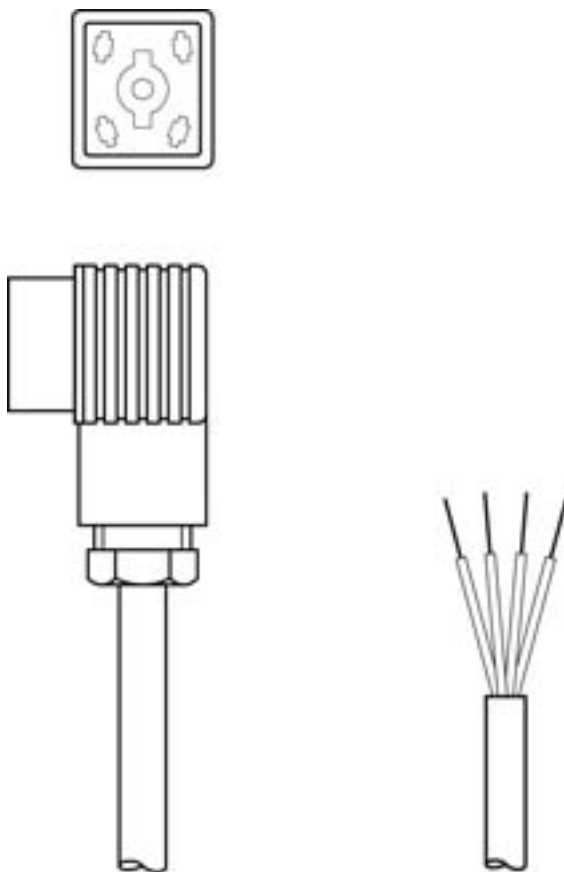

For illustration purposes only



## Technical data

### Basic data

|             |                    |
|-------------|--------------------|
| Application | Chemical resistant |
|-------------|--------------------|

### Electrical data

#### Performance data

|                   |            |
|-------------------|------------|
| Operating voltage | 30 V AC/DC |
|-------------------|------------|

### Connection

#### Connection 1

|                    |               |
|--------------------|---------------|
| Type of connection | Standard plug |
| Connector, LED     | No            |
| No. of pins        | 4 -pin        |
| Version            | Angled        |
| Type               | Female        |

#### Connection 2

|                    |          |
|--------------------|----------|
| Type of connection | Open end |
|--------------------|----------|

#### Cable properties

|                             |                                    |
|-----------------------------|------------------------------------|
| Number of conductors        | 4 Piece(s)                         |
| Sheathing color             | Black                              |
| Shielded                    | No                                 |
| Cable design                | Connection cable (open on one end) |
| Cable diameter (external)   | 4.7 mm                             |
| Cable length                | 12,000 mm                          |
| Sheathing material          | PVC                                |
| Suitability for drag chains | No                                 |

### Mechanical data

|            |       |
|------------|-------|
| Net weight | 371 g |
|------------|-------|

### Operation and display

### Environmental data

|                                |             |
|--------------------------------|-------------|
| Ambient temperature, operation | 5 ... 40 °C |
|--------------------------------|-------------|

### Classification

|                       |          |
|-----------------------|----------|
| Customs tariff number | 85444290 |
| ECLASS 5.1.4          | 27279201 |
| ECLASS 8.0            | 27279218 |
| ECLASS 9.0            | 27060311 |
| ECLASS 10.0           | 27060311 |
| ECLASS 11.0           | 27060311 |
| ECLASS 12.0           | 27060311 |
| ECLASS 13.0           | 27060311 |
| ECLASS 14.0           | 27060311 |
| ECLASS 15.0           | 27060311 |
| ECLASS 16.0           | 27060311 |
| ETIM 5.0              | EC001855 |
| ETIM 6.0              | EC001855 |
| ETIM 7.0              | EC001855 |
| ETIM 8.0              | EC001855 |
| ETIM 9.0              | EC001855 |
| ETIM 10.0             | EC001855 |

## Electrical connection

### Connection 1

|                    |               |
|--------------------|---------------|
| Type of connection | Standard plug |
| Connector, LED     | No            |
| No. of pins        | 4 -pin        |
| Version            | Angled        |
| Type               | Female        |

### Connection 2

|                    |          |
|--------------------|----------|
| Type of connection | Open end |
|--------------------|----------|

## Circuit diagrams

