


## Technical data sheet Interconnection cable

Part no.: 50104026

KB 031-7000-01

### Contents

- Technical data
- Electrical connection

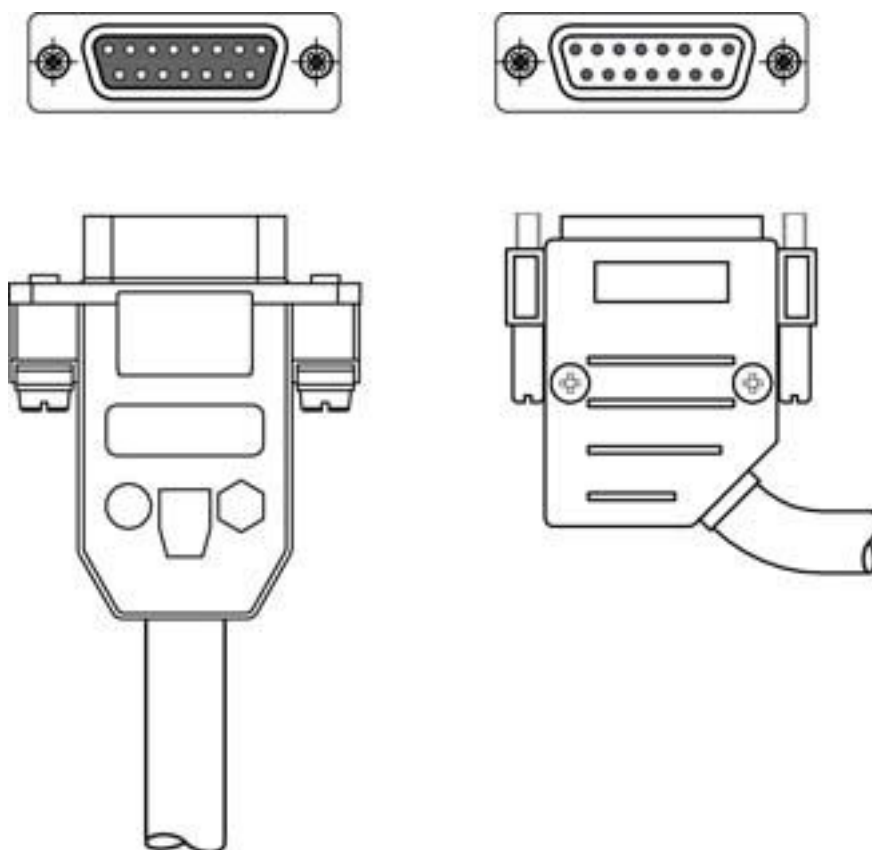

For illustration purposes only



## Technical data

### Basic data

### Electrical data

#### Performance data

Operating voltage	30 V AC/DC
-------------------	------------

### Connection

#### Connection 1

Type of connection	Sub-D
Connector, LED	No
Type	Female
No. of pins	15 -pin
Version	Axial

#### Connection 2

Type of connection	Sub-D
Type	Male
No. of pins	15 -pin
Version	Axial

#### Cable properties

Number of conductors	15 Piece(s)
Shielded	Yes
Cable design	Connection cable (open on one end)
Cable diameter (external)	8.1 mm
Cable length	7,000 mm
Suitability for drag chains	No

### Mechanical data

Net weight	583 g
------------	-------

### Operation and display

### Classification

Customs tariff number	85444290
ECLASS 5.1.4	27279201
ECLASS 8.0	27279218
ECLASS 9.0	27060311
ECLASS 10.0	27060311
ECLASS 11.0	27060311
ECLASS 12.0	27060311
ECLASS 13.0	27060311
ECLASS 14.0	27060311
ECLASS 15.0	27060311
ECLASS 16.0	27060311
ETIM 5.0	EC001855
ETIM 6.0	EC001855
ETIM 7.0	EC001855
ETIM 8.0	EC001855
ETIM 9.0	EC001855
ETIM 10.0	EC001855
UNSPSC 26.08	26121604

## Electrical connection

### Connection 1

Type of connection	Sub-D
Connector, LED	No
Type	Female
No. of pins	15 -pin
Version	Axial

### Connection 2

Type of connection	Sub-D
Type	Male
No. of pins	15 -pin
Version	Axial