

Technical data sheet


Adapter cable

Part no.: 50134949

KDS ET-RJ45-A-USB3-A-P4-000

Contents

- Technical data
- Electrical connection

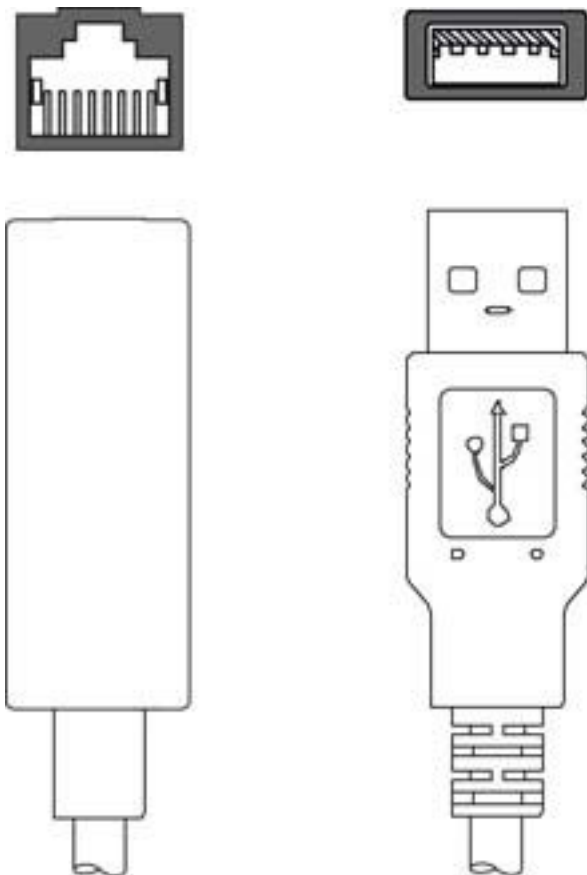

For illustration purposes only

Technical data

Basic data

Suitable for interface	Ethernet
------------------------	----------

Interface

Ethernet

Transmission speed	10/100/1000Mbps RJ45 Ethernet port
--------------------	------------------------------------

Connection

Number of connections	2 Piece(s)
-----------------------	------------

Connection 1

Type of connection	RJ45
Version	Axial

Connection 2

Type of connection	USB
Connector type	USB 3.0 Standard-A

Mechanical data

Design	Cubic
Dimension (W x H x L)	71 mm x 26 mm x 16.2 mm
Housing color	White

Environmental data

Ambient temperature, operation	0 ... 40 °C
Ambient temperature, storage	-40 ... 70 °C

Certifications

Degree of protection	IP 20
Approvals	FCC
	RoHS

Software

System requirements	Windows XP/Vista/7/8/8.1, Mac OS X 10.5/10.6/10.7/10.8/10.9/10.10/, Linux-based system
---------------------	--

Classification

Customs tariff number	85176200
ECLASS 5.1.4	27069190
ECLASS 8.0	27069190
ECLASS 9.0	27069190
ECLASS 10.0	27060313
ECLASS 11.0	27060313
ECLASS 12.0	27060313
ECLASS 13.0	27060313
ECLASS 14.0	27060313
ECLASS 15.0	27060313
ETIM 5.0	EC001855
ETIM 6.0	EC001855
ETIM 7.0	EC001855
ETIM 8.0	EC001855
ETIM 9.0	EC001855
ETIM 10.0	EC001855

Electrical connection

Connection 1

Type of connection	RJ45
--------------------	------

Connection 2

Type of connection	USB
Connector type	USB 3.0 Standard-A