

Technical data sheet

Adapter

Part no.: 50134904

KDS U-M8-4A-M8-3A-P1-000

Contents

- Technical data
- Electrical connection
- Circuit diagrams
- Accessories



For illustration purposes only



Technical data

Electrical data

Performance data

Operating voltage	Max. 50 V AC / 60 V DC
-------------------	------------------------

Connection

Connection 1

Type of connection	Connector
--------------------	-----------

Thread size	M8
-------------	----

Type	Female
------	--------

No. of pins	4 -pin
-------------	--------

Version	Axial
---------	-------

Connection 2

Type of connection	Connector
--------------------	-----------

Thread size	M8
-------------	----

Type	Male
------	------

No. of pins	3 -pin
-------------	--------

Version	Axial
---------	-------

Cable properties

Shielded	No
----------	----

Mechanical data

Width across flats	9 mm
--------------------	------

Material	PUR
----------	-----

Certifications

Degree of protection	IP 67
----------------------	-------

Classification

Customs tariff number	85366990
-----------------------	----------

ECLASS 5.1.4	27279201
--------------	----------

ECLASS 8.0	27440104
------------	----------

ECLASS 9.0	27069190
------------	----------

ECLASS 10.0	27440106
-------------	----------

ECLASS 11.0	27440106
-------------	----------

ECLASS 12.0	27440106
-------------	----------

ECLASS 13.0	27440106
-------------	----------

ECLASS 14.0	27440106
-------------	----------

ECLASS 15.0	27440106
-------------	----------

ETIM 5.0	EC002498
----------	----------

ETIM 6.0	EC002498
----------	----------

ETIM 7.0	EC002925
----------	----------

ETIM 8.0	EC002925
----------	----------

ETIM 9.0	EC002925
----------	----------

ETIM 10.0	EC002925
-----------	----------

Electrical connection

Connection 1

Type of connection	Connector
--------------------	-----------

Thread size	M8
-------------	----

Type	Female
------	--------

No. of pins	4 -pin
-------------	--------

Version	Axial
---------	-------

Connection 2

Type of connection	Connector
--------------------	-----------


Thread size	M8
-------------	----

Type	Male
------	------

No. of pins	3 -pin
-------------	--------

Version	Axial
---------	-------

Circuit diagrams

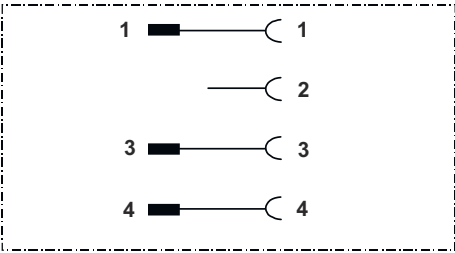

Accessories

General

	Part no.	Designation	Article	Description
	50132266	TT-Set 0,6-13	Tool	Type: Torque key Width across flats: 13 mm Torque: 0.6 N·m Material: Plastic, Stainless steel Ambient temperature: -40 ... 120 °C

Note



A list with all available accessories can be found on the Leuze website in the Download tab of the article detailed page.