

Technical data sheet

Connection cable

Part no.: 50110173

KB M12/8-10000-BA

Contents

- Technical data
- Electrical connection

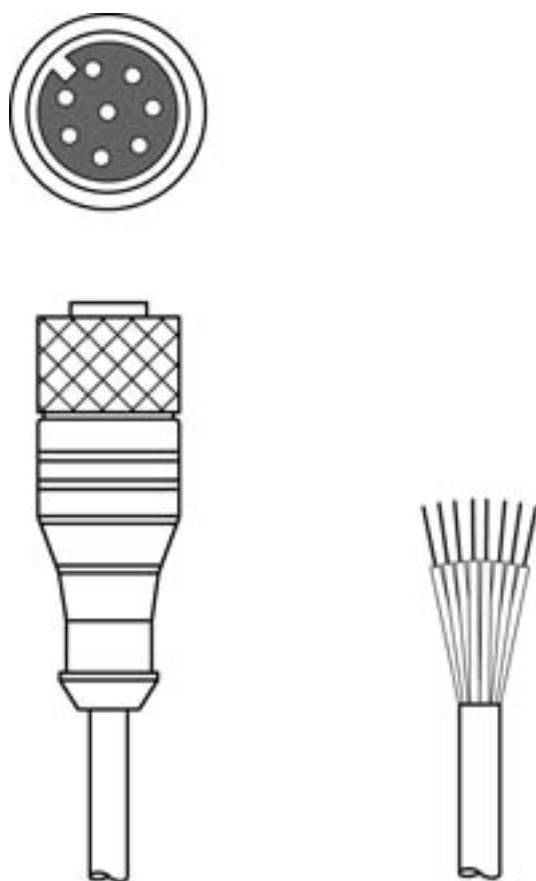


Figure can vary



Technical data

Connection

Connection 1

Type of connection	Connector
Thread size	M12
Type	Female
No. of pins	8 -pin
Encoding	A-coded
Design	Axial

Connection 2

Type of connection	Open end
--------------------	----------

Cable properties

Number of conductors	8 Piece(s)
Sheathing color	Gray
Shielded	No
Cable design	Connection cable (open on one end)
Cable diameter (external)	6.5 mm
Cable length	10,000 mm
Sheathing material	PUR

Classification

Customs tariff number	85444290
eCl@ss 8.0	27279218
eCl@ss 9.0	27060311
ETIM 5.0	EC001855
ETIM 6.0	EC001855

Electrical connection


Connection 1

Type of connection	Connector
Thread size	M12
Type	Female
No. of pins	8 -pin
Encoding	A-coded
Design	Axial

Pin

1	Brown
2	White
3	Blue
4	Black
5	Gray
6	Pink
7	Violet
8	Orange

Conductor color

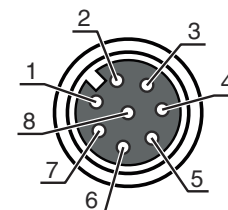

Connection 2

Type of connection	Open end
--------------------	----------