

Technical data sheet Interconnection cable

Part no.: 50113265

K-DS M12A-M12A-4P-10m-PVC

Contents

- Technical data
- Electrical connection

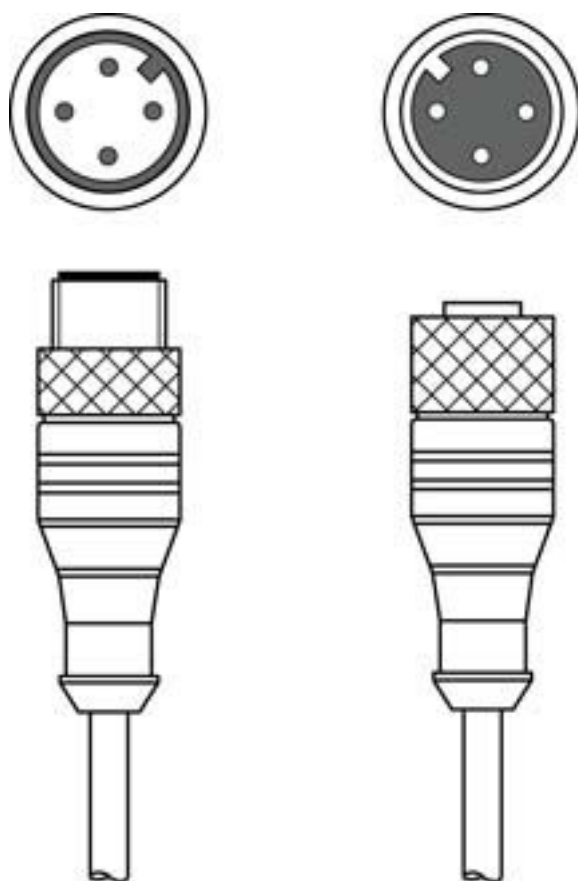


Figure can vary



Technical data

Connection

Connection 1

Type of connection	Connector
Thread size	M12
Type	Female
No. of pins	4 -pin
Encoding	A-coded
Design	Axial

Connection 2

Type of connection	Connector
Thread size	M12
Type	Male
No. of pins	4 -pin
Encoding	A-coded
Design	Axial

Cable properties

Number of conductors	4 Piece(s)
Wire cross section	0.34 mm ²
AWG	22
Sheathing color	Black
Shielded	No
Silicone-free	Yes
Cable design	Interconnection cable
Cable diameter (external)	5 mm
Cable length	10,000 mm
Sheathing material	PVC
Wire insulation	PVC
Suitability for drag chains	No
Properties of the outer sheathing	Free of CFC, cadmium, silicone and lead, easily machine-processable
Resistance of the outer sheathing	Good oil, gasoline and chemical resistance, flame retardant in accordance with UL 1581 VW1 / CSA FT1

Mechanical data

Bending radius, flexible laying, min.	Min. 10 x cable diameter
Bending radius, stationary laying, min.	Min. 5 x cable diameter

Environmental data

Ambient temperature, operation, flexible use	-5 ... 80 °C
Ambient temperature, operation, stationary use	-30 ... 80 °C

Certifications

Certifications	c UL US
----------------	---------

Classification

Customs tariff number	85444290
eCl@ss 8.0	27279218
eCl@ss 9.0	27060311
ETIM 5.0	EC001855
ETIM 6.0	EC001855

Electrical connection

Connection 1

Type of connection	Connector
Thread size	M12
Type	Female
No. of pins	4 -pin
Encoding	A-coded
Design	Axial

Connection 2

Type of connection	Connector
Thread size	M12
Type	Male
No. of pins	4 -pin
Encoding	A-coded
Design	Axial