



Technical data sheet Interconnection cable

Part no.: 50113397

KB JST-HS-300

Contents

- Technical data
- Electrical connection

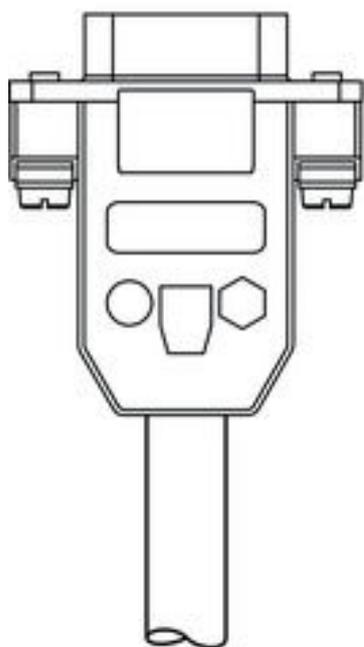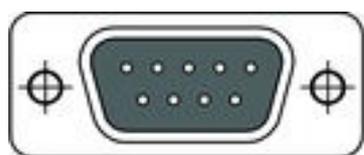

For illustration purposes only



Technical data

Basic data

Application	Chemical resistant
Suitable for interface	RS 232

Electrical data

Performance data

Operating voltage	30 V AC/DC
-------------------	------------

Connection

Connection 1

Type of connection	JST ZHR connector
No. of pins	12 -pin
Connector, LED	No

Connection 2

Type of connection	Sub-D
Type	Male
No. of pins	9 -pin
Version	Axial

Cable properties

Number of conductors	5 Piece(s)
Sheathing color	Black
Shielded	Yes
Cable design	Interconnection cable
Cable diameter (external)	5.5 mm
Cable length	300 mm
Sheathing material	PUR
Suitability for drag chains	No

Mechanical data

Net weight	49 g
------------	------

Operation and display

Classification

Customs tariff number	85444290
ECLASS 5.1.4	27279201
ECLASS 8.0	27279218
ECLASS 9.0	27060311
ECLASS 10.0	27060311
ECLASS 11.0	27060311
ECLASS 12.0	27060311
ECLASS 13.0	27060311
ECLASS 14.0	27060311
ECLASS 15.0	27060311
ECLASS 16.0	27060311
ETIM 5.0	EC001855
ETIM 6.0	EC001855
ETIM 7.0	EC001855
ETIM 8.0	EC001855
ETIM 9.0	EC001855
ETIM 10.0	EC001855

Electrical connection

Connection 1

Type of connection	JST ZHR connector
No. of pins	12 -pin
Connector, LED	No

Connection 2

Type of connection	Sub-D
Type	Male
No. of pins	9 -pin
Version	Axial