

Technical data sheet

Connection cable

Part no.: 50154369

KB 4AC1 050

Contents

- Technical data
- Dimensioned drawings
- Electrical connection

For illustration purposes only



Technical data

Basic data

Application	Oil and lubricant resistant
Suitable for interface	RS 232

Electrical data

Performance data

Operating voltage	30 V AC/DC
-------------------	------------

Connection

Connection 1

Type of connection	JST ZHR connector
No. of pins	4 -pin
Connector, LED	No

Connection 2

Type of connection	Open end
--------------------	----------

Cable properties

Number of conductors	4 Piece(s)
Sheathing color	Black
Shielded	No
Cable design	Connection cable (open on one end)
Cable diameter (external)	3.95 mm
Cable length	5,000 mm
Sheathing material	PVC
Suitability for drag chains	Yes

Mechanical data

Net weight	99 g
Bending cycles	5,000,000 Piece(s)


Operation and display

Classification

Customs tariff number	85444290
ECLASS 5.1.4	27279201
ECLASS 8.0	27279218
ECLASS 9.0	27060311
ECLASS 10.0	27060311
ECLASS 11.0	27060311
ECLASS 12.0	27060311
ECLASS 13.0	27060311
ECLASS 14.0	27060311
ECLASS 15.0	27060311
ECLASS 16.0	27060311
ETIM 5.0	EC001855
ETIM 6.0	EC001855
ETIM 7.0	EC001855
ETIM 8.0	EC001855
ETIM 9.0	EC001855
ETIM 10.0	EC001855

Dimensioned drawings

All dimensions in millimeters

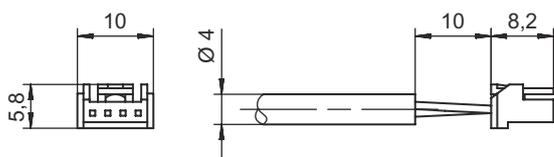

Electrical connection

Connection 1

Type of connection	JST ZHR connector
No. of pins	4 -pin
Connector, LED	No

Connection 2

Type of connection	Open end
--------------------	----------