


## Technical data sheet Interconnection cable

Part no.: 50113396

KB DSub-9P-3000

### Contents

- Technical data
- Electrical connection

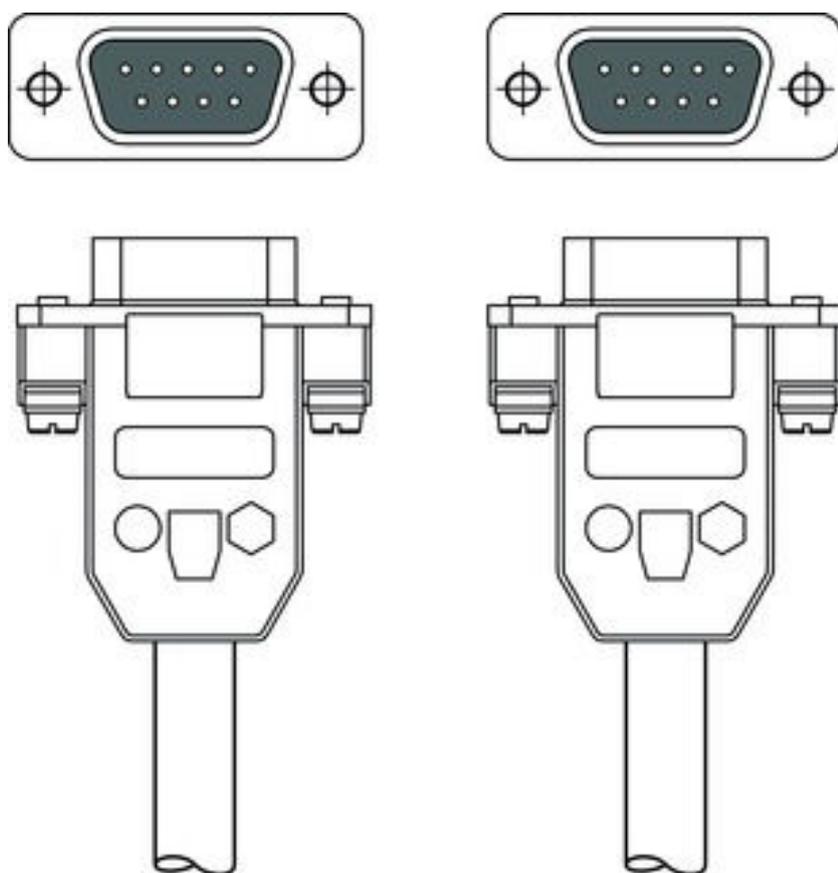

For illustration purposes only



## Technical data

### Basic data

Application	Oil and lubricant resistant
Suitable for interface	RS 232

### Connection

#### Connection 1

Function	Data interface
Type of connection	Sub-D
Connector, LED	No
Type	Female
No. of pins	9 -pin
Version	Axial

#### Connection 2

Function	Data interface
Type of connection	Sub-D
Type	Female
No. of pins	9 -pin
Version	Axial

#### Cable properties

Number of conductors	8 Piece(s)
Sheathing color	Gray
Shielded	Yes
Cable design	Interconnection cable
Cable diameter (external)	6 mm
Cable length	3,000 mm
Sheathing material	PVC
Suitability for drag chains	No

### Mechanical data

Net weight	118 g
------------	-------

### Operation and display

### Classification

Customs tariff number	85444290
ECLASS 5.1.4	27279201
ECLASS 8.0	27279218
ECLASS 9.0	27060311
ECLASS 10.0	27060311
ECLASS 11.0	27060311
ECLASS 12.0	27060311
ECLASS 13.0	27060311
ECLASS 14.0	27060311
ECLASS 15.0	27060311
ECLASS 16.0	27060311
ETIM 5.0	EC001855
ETIM 6.0	EC001855
ETIM 7.0	EC001855
ETIM 8.0	EC001855
ETIM 9.0	EC001855
ETIM 10.0	EC001855


## Electrical connection

### Connection 1

Function	Data interface
Type of connection	Sub-D
Connector, LED	No
Type	Female
No. of pins	9 -pin
Version	Axial

### Pin Pin assignment

1	DCD
2	RxD
3	TxD
4	DTR
5	GND
6	n.c.
7	RTS
8	CTS
9	RI

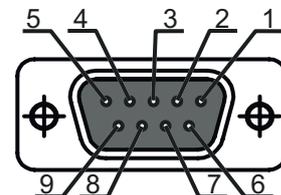

## Electrical connection

### Connection 2

Function	Data interface
Type of connection	Sub-D
Type	Female
No. of pins	9 -pin
Version	Axial

Pin	Pin assignment
1	DTR
2	TxD
3	RxD
4	DCD
5	GND
6	n.c.
7	CTS
8	RTS
9	RI

