

## Technical data sheet

### Connection cable

Part no.: 50154365

KB 4AV1 030

#### Contents

- Technical data
- Dimensioned drawings
- Electrical connection

For illustration purposes only



## Technical data

### Basic data

Application	Oil and lubricant resistant
Suitable for interface	RS 232

### Electrical data

#### Performance data

Operating voltage	30 V AC/DC
-------------------	------------

### Connection

#### Connection 1

Type of connection	JST ZHR connector
No. of pins	4 -pin
Connector, LED	No

#### Connection 2

Type of connection	Open end
--------------------	----------

#### Cable properties

Number of conductors	4 Piece(s)
Sheathing color	Black
Shielded	No
Cable design	Connection cable (open on one end)
Cable diameter (external)	3.95 mm
Cable length	3,000 mm
Sheathing material	PVC
Suitability for drag chains	No

### Mechanical data

Net weight	99 g
------------	------


### Operation and display

#### Classification

Customs tariff number	85444290
ECLASS 5.1.4	27279201
ECLASS 8.0	27279218
ECLASS 9.0	27060311
ECLASS 10.0	27060311
ECLASS 11.0	27060311
ECLASS 12.0	27060311
ECLASS 13.0	27060311
ECLASS 14.0	27060311
ECLASS 15.0	27060311
ECLASS 16.0	27060311
ETIM 5.0	EC001855
ETIM 6.0	EC001855
ETIM 7.0	EC001855
ETIM 8.0	EC001855
ETIM 9.0	EC001855
ETIM 10.0	EC001855

## Dimensioned drawings

All dimensions in millimeters

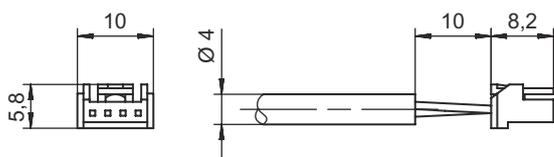

## Electrical connection

### Connection 1

Type of connection	JST ZHR connector
No. of pins	4 -pin
Connector, LED	No

### Connection 2

Type of connection	Open end
--------------------	----------