

## Technical data sheet



### Connection cable

Part no.: 50134977

KD U-M23-JW-P1-100

#### Contents

- Technical data
- Electrical connection

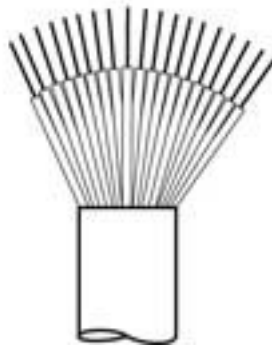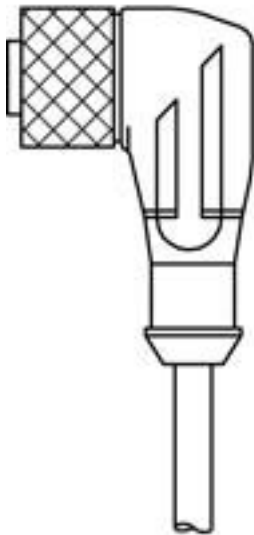

For illustration purposes only



Technical data

Basic data

|             |                             |
|-------------|-----------------------------|
| Application | Oil and lubricant resistant |
|-------------|-----------------------------|

Electrical data

|                   |                  |
|-------------------|------------------|
| Performance data  |                  |
| Operating voltage | Max. 120 V AC/DC |

Connection

|                                   |                                                                                                                                                         |
|-----------------------------------|---------------------------------------------------------------------------------------------------------------------------------------------------------|
| Connection 1                      |                                                                                                                                                         |
| Type of connection                | Connector                                                                                                                                               |
| Thread size                       | M23                                                                                                                                                     |
| Type                              | Female                                                                                                                                                  |
| Handle body material              | TPU                                                                                                                                                     |
| No. of pins                       | 19 -pin                                                                                                                                                 |
| Encoding                          | A-coded                                                                                                                                                 |
| Version                           | Angled                                                                                                                                                  |
| Connector, LED                    | No                                                                                                                                                      |
| Lock                              | Screw fitting, nickel-plated diecast zinc, recommended torque 0.6 Nm, self-locking                                                                      |
| Connection 2                      |                                                                                                                                                         |
| Type of connection                | Open end                                                                                                                                                |
| Cable properties                  |                                                                                                                                                         |
| Number of conductors              | 19 Piece(s)                                                                                                                                             |
| Wire cross section                | 0.5 mm²                                                                                                                                                 |
| Wire cross section                | 16 x 0.5 mm²                                                                                                                                            |
|                                   | 3 x 1 mm²                                                                                                                                               |
| AWG                               | 21                                                                                                                                                      |
| Sheathing color                   | Black                                                                                                                                                   |
| Shielded                          | No                                                                                                                                                      |
| Silicone-free                     | Yes                                                                                                                                                     |
| Cable design                      | Connection cable (open on one end)                                                                                                                      |
| Cable diameter (external)         | 11.6 mm                                                                                                                                                 |
| Cable length                      | 10,000 mm                                                                                                                                               |
| Sheathing material                | PUR                                                                                                                                                     |
| Wire insulation                   | PP                                                                                                                                                      |
| Suitability for drag chains       | Yes                                                                                                                                                     |
| Traversal rate                    | Max. 3.3 m/s with horiz. traverse path of 5m and and max. acceleration of 5m/s²                                                                         |
| Properties of the outer sheathing | Free of silicone and halogen, matt, low-adhesion, abrasion-resistant, easily machine-processable                                                        |
| Resistance of the outer sheathing | Hydrolysis and microbe resistant, good oil and chemical resistance, flame retardant in accordance with IEC 60332-2, VDE 0482-265-2-2, EN 50265-2-2, FT2 |

Mechanical data

|                                         |                          |
|-----------------------------------------|--------------------------|
| Bending cycles                          | 2,000,000 Piece(s)       |
| Bending radius, flexible laying, min.   | Min. 10 x cable diameter |
| Bending radius, stationary laying, min. | Min. 5 x cable diameter  |

Operation and display

|                                                |               |
|------------------------------------------------|---------------|
| Environmental data                             |               |
| Ambient temperature, operation, flexible use   | -25 ... 80 °C |
| Ambient temperature, operation, stationary use | -50 ... 80 °C |

Certifications

|                      |       |
|----------------------|-------|
| Degree of protection | IP 65 |
|                      | IP 67 |

Classification

|                       |          |
|-----------------------|----------|
| Customs tariff number | 85444290 |
| ECLASS 5.1.4          | 27279201 |
| ECLASS 8.0            | 27279218 |
| ECLASS 9.0            | 27060311 |
| ECLASS 10.0           | 27060311 |
| ECLASS 11.0           | 27060311 |
| ECLASS 12.0           | 27060311 |
| ECLASS 13.0           | 27060311 |
| ECLASS 14.0           | 27060311 |
| ETIM 5.0              | EC001855 |
| ETIM 6.0              | EC001855 |
| ETIM 7.0              | EC001855 |
| ETIM 8.0              | EC001855 |
| ETIM 9.0              | EC001855 |

Electrical connection

Connection 1

|                      |           |
|----------------------|-----------|
| Type of connection   | Connector |
| Thread size          | M23       |
| Type                 | Female    |
| Handle body material | TPU       |

Electrical connection

Connection 1

|                |                                                                                    |
|----------------|------------------------------------------------------------------------------------|
| No. of pins    | 19 -pin                                                                            |
| Encoding       | A-coded                                                                            |
| Version        | Angled                                                                             |
| Connector, LED | No                                                                                 |
| Lock           | Screw fitting, nickel-plated diecast zinc, recommended torque 0.6 Nm, self-locking |

| Pin | Conductor color |
|-----|-----------------|
| 1   | Violet          |
| 2   | Red             |
| 3   | Gray            |
| 4   | Blue / Red      |
| 5   | Green           |
| 6   | Blue            |
| 7   | Gray / Pink     |
| 8   | Green / White   |
| 9   | White / Yellow  |
| 10  | Gray / White    |
| 11  | Black           |
| 12  | Green / Yellow  |
| 13  | Brown / Yellow  |
| 14  | Brown / Green   |
| 15  | White           |
| 16  | Yellow          |
| 17  | Pink            |
| 18  | Brown / Gray    |
| 19  | Brown           |



Connection 2

|                    |          |
|--------------------|----------|
| Type of connection | Open end |
|--------------------|----------|